
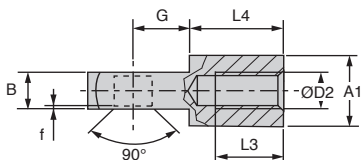
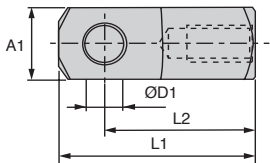


CLM CLMss

Steel or stainless steel

- Clevis link
- Threaded end piece for clevis conforming to **DIN71752, short version**
- Steel 11SMnPb30+C, galvanised
- Stainless steel 303

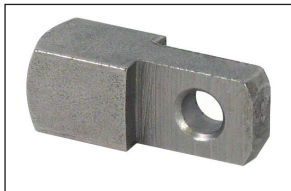

DISCOUNTS Steel

Qty	1+	10+	20+	50+
Disc.	List	-10%	-15%	On request





DISCOUNTS Stainless steel

Qty	1+	4+	10+	20+
Disc.	List	-10%	-15%	On request

Part number	ØD1 H9	ØD2	A1 B	L1 h11	L2 +/-0,5	L3 +/-0,3	L4 +/-0,2	G +/-0,5	f +/-0,2	Weight (g)	Price each 1 to 5
Steel											
CLM-4	4	M4x0,7	4	8	21	16	6	10,0	6,0	0,5	6 ✓ 1,92 €
CLM-5	5	M5x0,8	5	10	26	20	8	12,5	7,5	0,5	12 ✓ 1,85 €
CLM-6	6	M6x1	6	12	31	24	11	15,0	9,0	0,5	21 ✓ 2,69 €
CLM-8	8	M8x1,25	8	16	42	32	14	20,0	12,0	0,5	51 ✓ 3,64 €
CLM-10	10	M10x1,5	10	20	52	40	18	25,0	15,0	0,5	98 ✓ 3,43 €
CLM-12	12	M12x1,75	12	24	62	48	22	30,0	18,0	0,5	168 ✓ 8,05 €
CLM-16	16	M16x2	16	32	83	64	30	40,0	24,0	1,0	397 ✓ 10,08 €
Stainless steel											
CLM-4/SS	4	M4x0,7	4	8	21	16	6	10,0	6,0	0,5	6 ✓ 5,33 €
CLM-5/SS	5	M5x0,8	5	10	26	20	8	12,5	7,5	0,5	12 ✓ 7,56 €
CLM-6/SS	6	M6x1	6	12	31	24	11	15,0	9,0	0,5	21 ✓ 10,97 €
CLM-8/SS	8	M8x1,25	8	16	42	32	14	20,0	12,0	0,5	51 ✓ 9,52 €
CLM-10/SS	10	M10x1,5	10	20	52	40	18	25,0	15,0	0,5	98 - 8,98 €
CLM-12/SS	12	M12x1,75	12	24	62	48	22	30,0	18,0	0,5	168 - 12,55 €
CLM-16/SS	16	M16x2	16	32	83	64	30	40,0	24,0	1,0	397 - 36,10 €

*Depending on availability - Dimensions in mm

Instruction guide

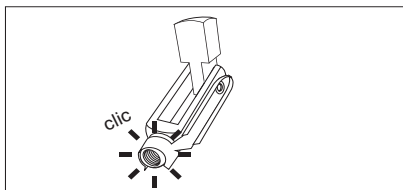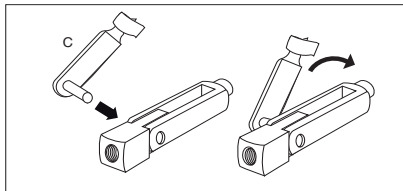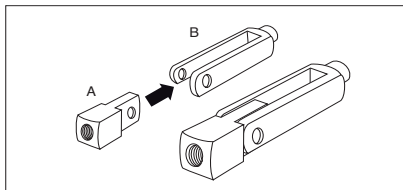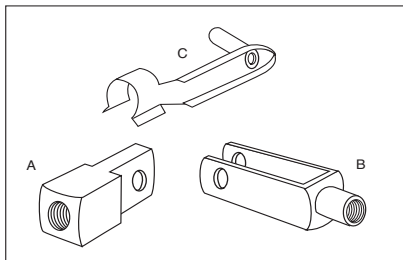

Our other products




VTLM
3 lobed handle,
Polyamide - Steel



S2B
Short linear bearing
housing, Closed - Slim



RURp
Fixed castor with
plate, Polyurethane -
Aluminium rim (Free
running)

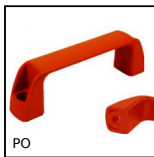

PO
Pull handle - Multi-
sector, Smooth hole



PT882
Drive sprocket for slat
top chain, Range 882



BABpss
301 Stainless steel
ball pin, Stainless
steel




MHXred
Reducing sleeve
male/female,
Hexagonal - stainless
steel



MSP3815
Masterplate®
glueable insert
rectangular,
rectangular with nut



 SHNbr
Hexagonal nut
DIN934, Brass



T5courroie
T type timing belt, T5
Steel cored
polyurethane



DB
Steel bevel gear, 2:1



RBGpl
Swivel castor with
plate, Steel - grey
rubber

Complementary products



CLM
Male clevis end, Steel
short



COA-COG
Surface mounting
plate, Surface
mounting plate for
clevis



CLR
Straight clevis,
Straight clevis for use
with a male clevis



CNA-CNG
Right angled
mounting plate, Right
angled mounting
plate for clevis