
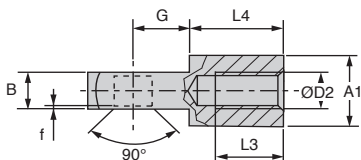
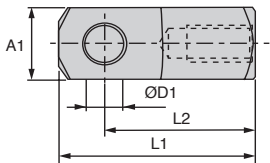


CLM CLMss

Steel or stainless steel

- Clevis link
- Threaded end piece for clevis conforming to **DIN71752, short version**
- Steel 11SMnPb30+C, galvanised
- Stainless steel 303

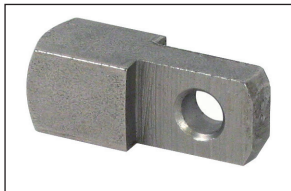

DISCOUNTS Steel

Qty	1+	10+	20+	50+
Disc.	List	-10%	-15%	On request





DISCOUNTS Stainless steel

Qty	1+	4+	10+	20+
Disc.	List	-10%	-15%	On request

Part number	ØD1 H9	ØD2	A1 B	L1 h11	L2 +/-0,5	L3 +/-0,3	L4 +/-0,2	G +/-0,5	f +/-0,2	Weight (g)	Price each 1 to 5		
Steel													
CLM-4	4	M4x0,7	4	8	21	16	6	10,0	6,0	0,5	6	✓	1,92 €
CLM-5	5	M5x0,8	5	10	26	20	8	12,5	7,5	0,5	12	✓	1,85 €
CLM-6	6	M6x1	6	12	31	24	11	15,0	9,0	0,5	21	✓	2,69 €
CLM-8	8	M8x1,25	8	16	42	32	14	20,0	12,0	0,5	51	✓	3,64 €
CLM-10	10	M10x1,5	10	20	52	40	18	25,0	15,0	0,5	98	✓	3,43 €
CLM-12	12	M12x1,75	12	24	62	48	22	30,0	18,0	0,5	168	✓	8,05 €
CLM-16	16	M16x2	16	32	83	64	30	40,0	24,0	1,0	397	✓	10,08 €
Stainless steel													
CLM-4/SS	4	M4x0,7	4	8	21	16	6	10,0	6,0	0,5	6	✓	5,33 €
CLM-5/SS	5	M5x0,8	5	10	26	20	8	12,5	7,5	0,5	12	✓	7,56 €
CLM-6/SS	6	M6x1	6	12	31	24	11	15,0	9,0	0,5	21	✓	10,97 €
CLM-8/SS	8	M8x1,25	8	16	42	32	14	20,0	12,0	0,5	51	✓	9,52 €
CLM-10/SS	10	M10x1,5	10	20	52	40	18	25,0	15,0	0,5	98	-	8,98 €
CLM-12/SS	12	M12x1,75	12	24	62	48	22	30,0	18,0	0,5	168	-	12,55 €
CLM-16/SS	16	M16x2	16	32	83	64	30	40,0	24,0	1,0	397	-	36,10 €

*Depending on availability - Dimensions in mm

Instruction guide

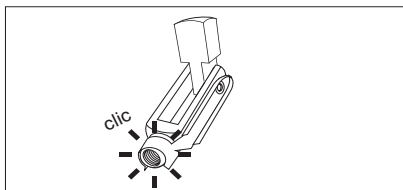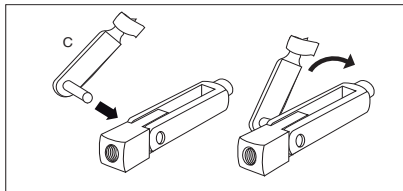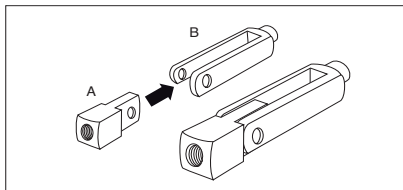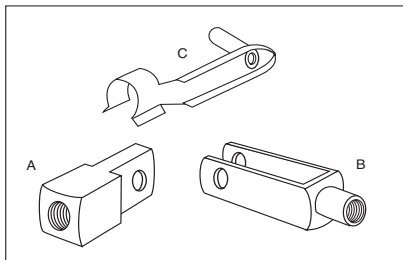

Our other products



BTC20_10

End cap for rectangular tube, Standard



PCS6ECO

Chain sprocket - steel, 6mm (DIN 04-1)



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



SSB

Stainless steel bevel gear, 1:1



PRF-SCL

Lock for aluminium profile, Lock for sliding doors



SSG0

Stainless steel spur gear, Stainless steel 304L



ACAss

Stainless steel splined shaft, Stainless steel



ACLBTS

Closing system for aluminium profile, Spacer for spherical ended stop



BL15

Right angled gearbox, from 1.10 to 6 Nm



HD

Double needle roller universal joint, Heavy



DER63

Stainless steel AC asynchronous motor



KSTM

Igubal® pillow block bearing, Polymer

Complementary products



CLM

Male clevis end, Steel short



COA-COG

Surface mounting plate, Surface mounting plate for clevis



CLR

Straight clevis, Straight clevis for use with a male clevis



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis