

- Kit of assorted precision feelers for adjusting, equalising, fixing or positioning
- To be cut to form required
- Materials:
 - Steel 1.1274
 - Stainless steel 1.4310
 - Brass 2.0321

Advantage

- Wide range of thicknesses in each box allows accurate positioning for all applications

Applications

- Aligning workpieces before machining, aligning differently sized/shaped pieces, adjusting valve lash, wedging tools, adjusting bearings



DISCOUNTS

Qty	1+	3+	5+
Disc.	List	-5%	On request

Part number	Number		Material	Contents of box	Stock*	Price each 1 to 2
	Format	Sheets				
CLQ25-300-21/A	25x300	21	steel 1.1274	0,01/0,02/0,03/0,04/0,05/0,06/ 0,07/0,08/0,09/0,10/0,15/0,20/ 0,25/0,30/0,40/0,50/0,60/0,70/ 0,80/0,90/1,00	✓	48,05 €
CLQ50-300-25/A	50x300	25	steel 1.1274	0,01/0,02/0,03/0,04/0,05/0,06/0,07/ 0,08/0,09/0,10/0,12/0,15/0,18/0,20/ 0,25/0,30/0,35/0,40/0,45/0,50/ 0,60/0,70/0,80/0,90/1,00	✓	83,20 €
CLQ50-300-23/A	50x300	23	steel 1.1274	0,03/0,04/0,05/0,06/0,07/0,08/ 0,09/0,10/0,12/0,15/0,18/0,20/ 0,25/0,30/0,35/0,40/0,45/0,50/ 0,60/0,70/0,80/0,90/1,00	✓	68,99 €
CLQ100-500-9/SS	100x500	9	s/steel 1.4310	0,02/0,05/0,10/0,15/0,20/0,30/ 0,40/0,50/1,00	✓	99,51 €
CLQ100-500-11/SS	100x500	11	s/steel 1.4310	0,02/0,05/0,10/0,15/0,20/0,25/ 0,30/0,35/0,40/0,45/0,50	✓	100,78 €
CLQ100-500-11/SS2	100x500	11	s/steel 1.4310	0,50/0,55/0,60/0,70/0,75/0,80/ 0,85/0,90/0,95/1,00	-	227,97 €
CLQ150-500-10/SS	150x500	10	s/steel 1.4310	0,025/0,05/0,075/0,1/0,15/0,20/ 0,25/0,30/0,50	-	143,19 €
CLQ150-500-10/BR	150x500	10	brass 2.0321	0,025/0,05/0,075/0,1/0,15/0,20/ 0,25/0,30/0,50	-	167,98 €


*Depending on availability - Dimensions in mm

Our other products



PSG05

Spur gear - precision range, Pre-hardened Steel 35NCD6

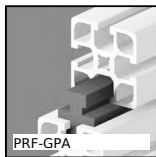

PRF-GPA

Guide for aluminium profile, Parallel rails



GB-RA

Brass spur gear, Brass CuZn39Pb3



HLA28

Right angle spiro bevel gearbox, Up to 182Nm



PTKss

Foot for the food industry, Stainless steel - 3-A standard



PGM52-M4

Pull handle, Brass



FF40

Offset spur gear reducer, from 59 to 210 Nm



PRF_JL6

Lip seal for panel, Door seal - Ø 6mm



FHCSS

Countersunk screw, Stainless steel A2 - DIN 7991



TFR

Rigid manual tensioner, Fixed



MRA_SS

Stainless steel Quick link, Stainless steel



EHD12

Internal epicyclic servo reducers, from 60 to 140 Nm

Complementary products



CLQ

12.7mm wide steel feeler strip on rolls, Feeler strip on rolls