

- Kit of assorted precision feelers for adjusting, equalising, fixing or positioning
- To be cut to form required
- Materials:
  - Steel 1.1274
  - Stainless steel 1.4310
  - Brass 2.0321

### Advantage

- Wide range of thicknesses in each box allows accurate positioning for all applications

### Applications

- Aligning workpieces before machining, aligning differently sized/shaped pieces, adjusting valve lash, wedging tools, adjusting bearings



### DISCOUNTS

Qty	1+	3+	5+
Disc.	List	-5%	On request

Part number	Number		Material	Contents of box	Stock*	Price each 1 to 2
	Format	Sheets				
CLQ25-300-21/A	25x300	21	steel 1.1274	0,01/0,02/0,03/0,04/0,05/0,06/ 0,07/0,08/0,09/0,10/0,15/0,20/ 0,25/0,30/0,40/0,50/0,60/0,70/ 0,80/0,90/1,00	✓	48,05 €
CLQ50-300-25/A	50x300	25	steel 1.1274	0,01/0,02/0,03/0,04/0,05/0,06/0,07/ 0,08/0,09/0,10/0,12/0,15/0,18/0,20/ 0,25/0,30/0,35/0,40/0,45/0,50/ 0,60/0,70/0,80/0,90/1,00	✓	83,20 €
CLQ50-300-23/A	50x300	23	steel 1.1274	0,03/0,04/0,05/0,06/0,07/0,08/ 0,09/0,10/0,12/0,15/0,18/0,20/ 0,25/0,30/0,35/0,40/0,45/0,50/ 0,60/0,70/0,80/0,90/1,00	✓	68,99 €
CLQ100-500-9/SS	100x500	9	s/steel 1.4310	0,02/0,05/0,10/0,15/0,20/0,30/ 0,40/0,50/1,00	✓	99,51 €
CLQ100-500-11/SS	100x500	11	s/steel 1.4310	0,02/0,05/0,10/0,15/0,20/0,25/ 0,30/0,35/0,40/0,45/0,50	✓	100,78 €
CLQ100-500-11/SS2	100x500	11	s/steel 1.4310	0,50/0,55/0,60/0,70/0,75/0,80/ 0,85/0,90/0,95/1,00	-	227,97 €
CLQ150-500-10/SS	150x500	10	s/steel 1.4310	0,025/0,05/0,075/0,1/0,15/0,20/ 0,25/0,30/0,50	-	143,19 €
CLQ150-500-10/BR	150x500	10	brass 2.0321	0,025/0,05/0,075/0,1/0,15/0,20/ 0,25/0,30/0,50	-	167,98 €

\*Depending on availability - Dimensions in mm

## Our other products



PSG125

Spur gear - precision range, Case hardened steel 20NCD2



BOX-TOR-B

Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



CHAFR

Adjustable friction hinges, Friction



P40

Worm and wheel gear reducer, up to 18 Nm



RTN

BoWex® curved tooth gear coupling, Nylon



ES

Bipod support base, Plastic



BPFL

Sheet steel flanged bearing for light loads, Sheet steel



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



HTD8M\_30

HTD Heavy duty timing pulley, HTD8 Steel




CHAGC-AL

Screw-in garnet hinge, Screw-on



CLSCLP

Clevis components, short version, Steel - short range

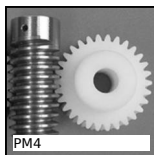

PM4

Worm and wheel set, Machined plastic (delrin)

## Complementary products



CLQ

12.7mm wide steel feeler strip on rolls, Feeler strip on rolls