


For use with a male clevis

CLR
CLRss

- For fixing a gas spring
- Materials:
 - Steel
 - 316L stainless steel

Advantages

- Allows gas springs to be mounted using a mounting plate and a CLM male clevis

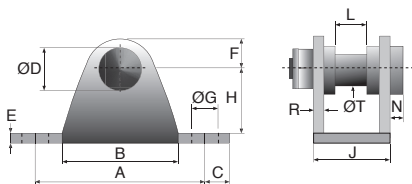**NEW!****DISCOUNTS**

Qty	1+	6+	10+	15+	20+
Disc.	List	-10%	-15%	-20%	On request

Part number	A	B	C	E	F	ØG	H	J	ØD	ØT	N	L	R	Max load (N)	Price each 1 to 5
Steel															
CLR-6	51	36	9,5	2,5	9	6,5	20	18	13	6	4,0	6,5	2,5	500	15,46 €
CLR-8	51	36	9,5	2,5	9	6,5	20	18	13	8	4,0	13	2,5	1800	15,46 €
Stainless steel															
CLR-6/SS	51	36	9,5	2,5	9	6,5	20	18	13	6	4,0	6,5	2,5	500	110,64 €
CLR-8/SS	51	36	9,5	2,5	9	6,5	20	18	13	8	4,0	13	2,5	1800	101,71 €

Dimensions in mm

 
Our other products



SSG1_304L
Stainless steel spur gear, Stainless steel 304L




BABS
630 Stainless steel compact ball pin, Hardened stainless steel



M1
Worm and wheel set, Machined plastic (delrin)



 PCM
Fixed cylindrical handle, Fixed non-turning handle



PO
Pull handle - Multi-sector, Smooth hole



LRRss
Latch, Spring loaded latch - stainless steel



ACM_AZ
Mounting bracket for bonnet fastener, Hook



PO
Pull handle - Multi-sector, Smooth hole



CHAuss
Screwed hinge, 270°



BPPL
Mini plain bearing ball transfer unit, For countersinking



T5-16ECO
T type timing pulley, Economy range - T5 aluminium



CAMTH
Thermal camera for use with smartphone, iOS and Android

Complementary products



CLM
Male clevis end, Steel short



GA
Gas spring, Steel



GA_A
Adjustable gas spring, Steel



COA-COG
Surface mounting plate, Surface mounting plate for clevis