

# Clevis and clip, short version




CLSSs  
CLPSSs


With **stainless steel** circlips

- Trunnion link
- Material: stainless steel 303
- To DIN 71752, DIN 471-UNI7435
- Spring clip supplied with 2 circlips

Clevis CLS-SS

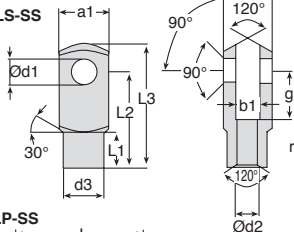

Clip CLP-SS

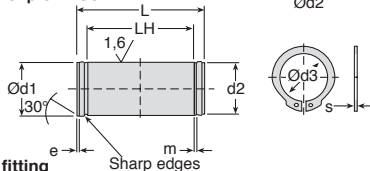

End fitting

Sharp edges

stainless steel



Clip CLP-SS



CLS-SS



CLP-SS

## DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-10%	-20%	On request

Part number	Ød2 (6H)	b1 (B13)	a1 (h11)	a2	Ød1 (h9)	d3 <sup>+0,3</sup>	L1 <sup>+0,2</sup>	L3 <sup>+0,5</sup>	L2 <sup>+0,3</sup>	g <sup>+0,5</sup>	Static load Co (daN)	Stock*	Price each 1 to 5
												✓	€
CLS-5SS	M5	5	10	10 <sup>+0,30</sup> <sub>-0,16</sub>	5	9	7,5	26	20	10	500	✓	6,36 €
CLS-6SS	M6	6	12	12 <sup>+0,30</sup> <sub>-0,16</sub>	6	10	9,0	31	24	12	720	✓	6,82 €
CLS-8SS	M8	8	16	16 <sup>+0,30</sup> <sub>-0,16</sub>	8	14	12,0	42	32	16	1280	✓	11,47 €
CLS-10CSS	M10x1,25	10	20	20 <sup>+0,30</sup> <sub>-0,16</sub>	10	18	15,0	52	40	20	-	✓	26,47 €
CLS-12SS	M12x1,75	12	24	24 <sup>+0,30</sup> <sub>-0,16</sub>	12	20	18,0	62	48	24	2880	✓	34,49 €
CLS-16CSS	M16x1,5	16	32	32 <sup>+0,30</sup> <sub>-0,16</sub>	16	26	24,0	83	64	32	-	✓	81,44 €
CLS-20CSS	M20x1,5	20	40	40 <sup>+0,50</sup> <sub>-0,20</sub>	20	34	30,0	105	80	40	-	-	On request

## Trunnion clip

Références	Ød1 (h11)	d2	L <sup>+0,3</sup>	LH <sup>+0,3</sup>	m (H13)	e	Ød3	s (h11)	Circlip size	Stock*	Price each. 1 to 5
										✓	€
CLP-5SS	5	4,8 <sup>0</sup> <sub>-0,048</sub>	15,0	10,5	0,7	0,5	4,7 <sup>+0,04</sup> <sub>-0,15</sub>	0,6	0,6	✓	2,23 €
CLP-6SS	6	5,7 <sup>0</sup> <sub>-0,048</sub>	17,0	12,5	0,8	0,5	5,6 <sup>+0,04</sup> <sub>-0,15</sub>	0,7	0,7	✓	2,17 €
CLP-8SS	8	7,6 <sup>0</sup> <sub>-0,058</sub>	21,5	16,5	0,9	0,5	7,4 <sup>+0,06</sup> <sub>-0,18</sub>	0,8	0,8	✓	2,40 €
CLP-10SS	10	9,6 <sup>0</sup> <sub>-0,068</sub>	26,0	20,5	1,1	0,5	9,3 <sup>+0,1</sup> <sub>-0,36</sub>	1,0	1,0	✓	2,61 €
CLP-12SS	12	11,5 <sup>0</sup> <sub>-0,110</sub>	31,0	24,5	1,1	1,0	11,0 <sup>+0,1</sup> <sub>-0,36</sub>	1,0	1,0	✓	3,63 €
CLP-16SS	16	15,2 <sup>0</sup> <sub>-0,110</sub>	40,0	32,5	1,1	1,0	14,7 <sup>+0,1</sup> <sub>-0,36</sub>	1,0	1,0	✓	3,60 €
CLP-20SS	20	19,0 <sup>0</sup> <sub>-0,130</sub>	50,0	40,5	1,3	1,5	18,5 <sup>+0,13</sup> <sub>-0,42</sub>	1,2	1,2	✓	9,03 €

\*Depending on availability - Dimensions in mm

## Our other products



CLASS

Stainless steel indexing handle - female, Stainless steel



DKONSL

Silicone conical elasto buffer, Male mounting



ACLPP

Latch for aluminium profile, Spring operated latch



P70

Worm and wheel gear reducer, up to 164 Nm



ACLCHAR

Hinge for aluminium profile, With elongated holes



BLHT70

Right angled gearbox, from 26 to 128 Nm



YG2

HEAVY DUTY spur gear, Steel 35NCD6



VQTplq

Quarter-turn clamp lock - Clamping plate, Flush mounting



DSF

Slip friction clutch, 4 to 2600 Nm



 
ZDB

Machined plastic bevel gear, 2:1



BOX-TOR-C

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x



NRR

Adjustable support clamp, Adjustable support clamp

## Complementary products



CLSCLP\_SS

Clevis components, short version, Stainless steel - short range



CLSCLP

Clevis components, short version, Steel - short range



CLM

Male clevis end, Stainless steel short