

Swivelling base clevis

CLS-R
CLL-R

Long and short ranges

- Clevis similar to DIN71752


- Materials:

Steel 11SMnPb30

white galvanised finish

Advantages

- The possibility to make adjustments after installation removes the need to have a left-handed thread

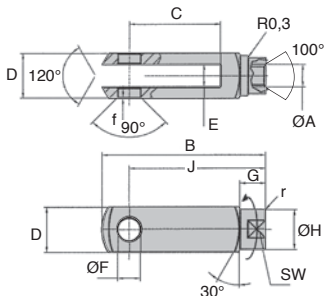

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-10%	-20%	-30%	-40%	On request

Part number	ØA	B	C (+/-0,5)	D	E	ØF (H9)	G	ØH	J	SW	Static load Co(daN)	Price each 1 to 5
Short range												
CLS-5R	M5x0,8	36	20	10	5	5	4	8,8	30	7	80	5,33 €
CLS-6R	M6x1	43	24	12	6	6	5,6	10,2	36	9	240	5,63 €
CLS-8R	M8x1,25	42	16	16	8	8	8,2	14	32	12	340	5,86 €
CLS-10R	M10x1,5	52	20	20	10	10	11,8	17,8	40	16	600	6,97 €
CLS-12R	M12x1,75	62	24	24	12	12	14	20	48	18	1400	8,48 €
Long range												
CLL-8R	M8x1,25	58	32	16	8	8	8,2	14	48	12	340	6,51 €
CLL-10R	M10x1,5	72	40	20	10	10	11,5	17,8	60	16	600	7,86 €
CLL-12R	M12x1,75	86	48	24	12	12	14	20	72	18	1400	11,58 €

Dimensions in mm

Our other products



Wheel, Bronze



Spur gear, Moulded blue plastic (nylon)



Locking pin, with ring



U bolt, Stainless steel



Curved tooth coupling, economy range, Steel and polyamide



Chain sprocket - steel, 12.7mm (DIN08B-1)



Solid foot for heavy loads, Ø 100, 120 or 150



Actuator guide kit, Short bearing



Ball and socket joint, Steel



Worm, Machined plastic (delrin)



Index bolt, miniature - Stainless steel



Modular cylindrical brush, Driving collar

Complementary products