


- Eye bolt
- Stamped ring, closed
- Conforms to UNI 6058
- ISO thread
- Material: Blackened steel C40

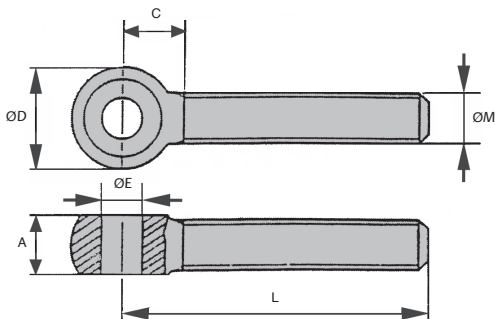

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØM	L	A	C	ØD	ØE	Weight (kg)	Stock*	Price each 1 to 19
CMA1-06	M6	50	7	8,5	12	5	0,012	✓	7,17 €
CMA1-08	M8	60	9	11,1	16	6	0,025	✓	7,47 €
CMA1-10	M10	80	12	13,8	20	8	0,048	✓	10,32 €
CMA1-12	M12	90	14	16,4	24	10	0,088	✓	12,19 €
CMA1-14	M14	120	16	19,0	28	12	0,153	✓	16,19 €
CMA1-16	M16	140	18	21,0	32	14	0,303	✓	16,59 €
CMA1-18	M18	150	20	24,2	36	16	0,328	-	18,51 €
CMA1-20	M20	160	22	26,2	40	18	0,431	✓	22,98 €

\*Depending on availability - Dimensions in mm

## Our other products



Compression springs  
in metre length steel,  
by the metre



630 Stainless steel  
compact ball pin,  
Hardened stainless  
steel



Telescopic drawer  
with damper,



Fastener for  
aluminium profile,  
Standard fastener



T-Clip - Aluminium  
profile attachment, T-  
Clip



 
Bearing locknut, Self  
locking locknut - nylon  
lock washer



Cam follower,  
Standard - steel



Speed controller 5A, 5  
A



Speed controller 3A, 3  
A



Utilitak® V rail, V rail



Cylindrical polymer  
nut, Polymer



Internal gear, Steel  
20NCD2

## Complementary products



Eye bolt stainless  
steel, Stainless steel