



Protective inserts for combination spanner

Hygienic Usit® and Hygienic Design® CMHDCO CMHDCF


- Protective inserts to be used with the CM combination spanner for mounting Hygienic Usit® and Hygienic Design® products

- Material:

Inserts: AlSi1MgMn

Advantages

- The protective caps have been specifically designed for fastening and un-fastening screwed connections with delicate surfaces.
- The protective caps will safely avoid the risk of contact corrosion with stainless steel screwed connections.
- The inserts are made of aluminium alloy EN AW 602 – a special aluminium suitable for contact with foodstuffs
- The protective cap is safely held in the spanner thanks to its special form and a sprung clip.

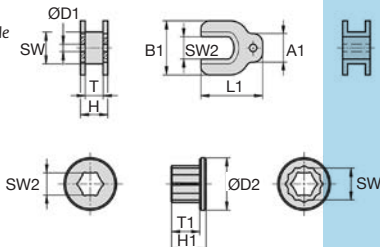

DISCOUNTS

Qty	1+	5+	10+
Disc.	Net	-5%	On request

Part N°	For spanner	SW	SW2	A1	B1	ØD1	ØD2	L1	T	T1	H	H1	Price each
													1 to 4
For open-ended spanner													
CM-10/HD/CF	CM-10/HD	10	7	9	17	2,3	-	19,4	5,6	-	8,6	-	18,84
CM-11/HD/CF	CM-11/HD	11	8	9	18	2,3	-	20,7	5,7	-	8,7	-	18,84
CM-13/HD/CF	CM-13/HD	13	10	10	22	3	-	23,2	6,7	-	10,7	-	19,05
CM-16/HD/CF	CM-16/HD	16	13	13	27	3	-	28,6	7,7	-	11,7	-	20,38
CM-19/HD/CF	CM-19/HD	19	16	13	30	4	-	32,5	8,6	-	12,6	-	21,54
CM-21/HD/CF	CM-21/HD	21	18	13	32	4	-	35,0	9,0	-	13,0	-	21,76
CM-27/HD/CF	CM-27/HD	27	24	14	40	4	-	43,8	10,8	-	15,0	-	23,26
For ring spanner													
CM-10/HD/CO	CM-10/HD	10	7	-	-	-	17	-	-	8,0	-	11,0	13,11
CM-11/HD/CO	CM-11/HD	11	8	-	-	-	18	-	-	9,4	-	11,4	13,11
CM-13/HD/CO	CM-13/HD	13	10	-	-	-	21	-	-	11,0	-	13,0	13,80
CM-16/HD/CO	CM-16/HD	16	13	-	-	-	25	-	-	12,4	-	14,4	14,15
CM-19/HD/CO	CM-19/HD	19	16	-	-	-	30	-	-	14,5	-	16,5	15,33
CM-21/HD/CO	CM-21/HD	21	18	-	-	-	32	-	-	14,7	-	16,7	15,43
CM-27/HD/CO	CM-27/HD	27	24	-	-	-	41	-	-	17,0	-	19,0	17,30

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

63

Our other products



BPF1s
Pressed stainless steel flange bearing, Stainless steel



COA-COG
Surface mounting plate, Surface mounting plate for ball joint



HW_HT
Half-rail guide, Rail



TCL
T-Clip - Aluminium profile attachment, T-Clip



PRF_RR
Coupling bar for aluminium profile, Coupling bar



 
TFR
Rigid manual tensioner, Fixed




UCP
Cast iron pillow block bearing, Cast iron



CPAS
Stay with safety catch, Opens upward



RPP14
RPP heavy duty timing belt, RPP14

 

PF40
Worm and wheel gear reducer, up to 18 Nm



PPC5s
Pad eye on mounting plate squarred, Stainless steel



T5M T10M
T type timing belt per metre, T10 Steel cored polyurethane

Complementary products



CM
Tools Hygienic Usit® and Hygienic Design®, Combination spanner



CM_CO
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...