



Stainless steel folding bracket

For heavy loads



CPAS

- **Folding bracket**
- Automatic locking when in the open position
- Opening sens to the top
- Unlocking lever
- Materials:



Stainless steel 304 polished finish

Advantage

- Angle bracket with integrated hinge function

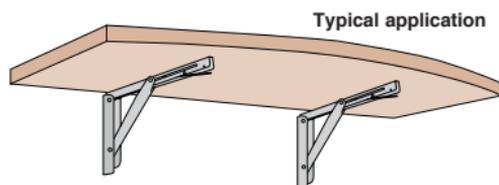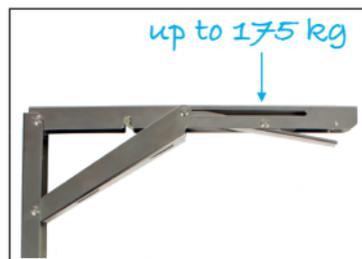

Typical application

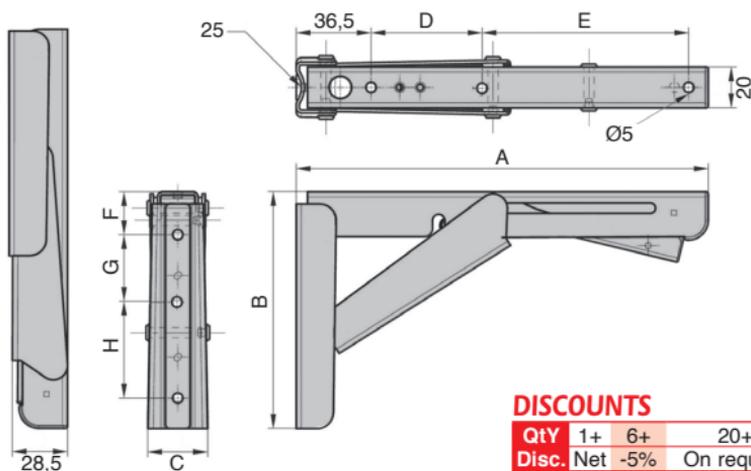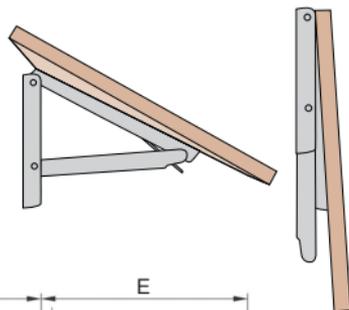

DISCOUNTS

Qty	1+	6+	20+
Disc.	Net	-5%	On request

Part N°	A	B	C	D	E	H	F	G	Admissible load (kg)	Weight (g)	Stock*	Price each 1 à 5
CPAS305-165H	307	165	29	98	156	67	38	45	150	515	✓	153,92 €
CPAS200-116H	201	116	29	155	-	-	21	80	175	332	New ✓	120,17 €

*Depending on availability - Dimensions in mm

Our other products



SSDB

Stainless steel bevel gear, 2:1



BFM2

Flanged bronze nut, Bronze - 2 threads



SER

Magnetic doorstop for aluminium profile, Magnetic doorstop



RDCss

Rigging screw with 2 jaws stainless steel, Stainless steel



DZY

Cylindrical stop, Steel



PO

Pull handle - Multi-sector, Smooth hole




GB-RA

Brass spur gear, Brass CuZn39Pb3



HCA

Magnetic screw with socket, Steel

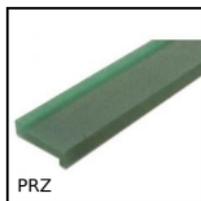

PRZ

Wear strip for slat top chain, Z profile to be



PSPE20

Conical flexible shaft handle Ø20, Black



SLVVIok

Vertical toggle clamp, Vertical toggle clamp /



UGH25

H Type Guide units, For Ø25 actuators

Complementary products



CPAS

Stay with safety catch, Opens upward