



Stainless steel folding bracket

For heavy loads



CPAS

- **Folding bracket**
- Automatic locking when in the open position
- Opening sens to the top
- Unlocking lever
- Materials:



Stainless steel 304 polished finish

Advantage

- Angle bracket with integrated hinge function

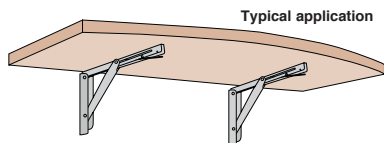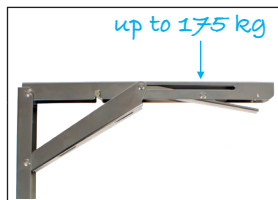

Typical application

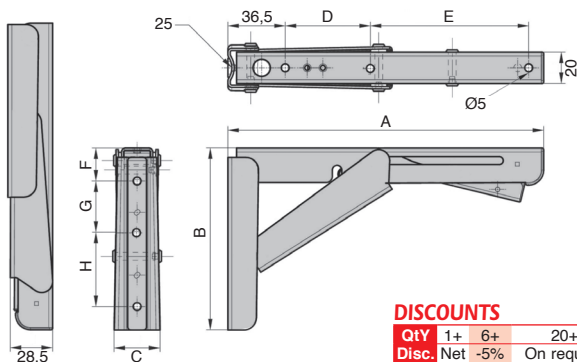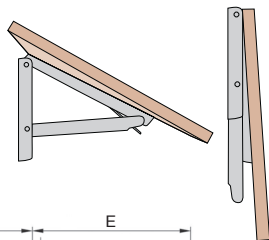

DISCOUNTS

Qty	1+	6+	20+
Disc.	Net	-5%	On request

Part N°	A	B	C	D	E	H	F	G	Admissible load (kg)	Weight (g)	Stock*	Price each 1 à 5
CPAS305-165H	307	165	29	98	156	67	38	45	150	515	✓	153,92 €
CPAS200-116H	201	116	29	155	-	-	21	80	175	332	New ✓	120,17 €

*Depending on availability - Dimensions in mm

Our other products



FF10

Offset spur gear reducer, from 0.78 to 3.70 Nm



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...



BPHRF

Ball transfer unit housed spring loaded, High



KSM

Cylindrical steel nut, Steel - 1 thread



CLB_T

Die cast zinc clamping lever - male, Zamak



 
ES

Support base (tripod), Plastic



BZY

Cylindrical elasto mount, Steel



B

Steel bevel gear, 1:1



PW_PWG1

Worm - precision range, Steel



DKGS

Backlash free coupling Gerwah®, from 0.5 to 3Nm



PRF_SDD

Support for Ø12mm Prox detector, Ø12



VRM

Female swivelling lifting rings, Female swivelling

Complementary products



CPAS

Stay with safety catch, Opens upward