



Stainless steel folding bracket

For heavy loads



CPAS

- **Folding bracket**
- Automatic locking when in the open position
- Opening sens to the top
- Unlocking lever
- Materials:



Stainless steel 304 polished finish

Advantage

- Angle bracket with integrated hinge function

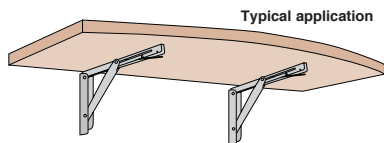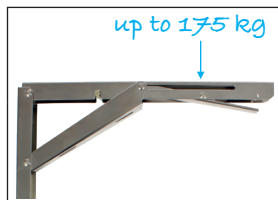

Typical application

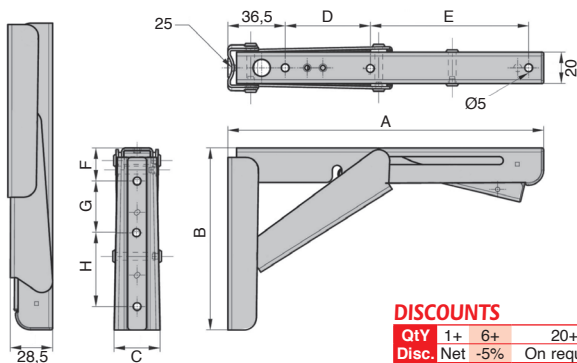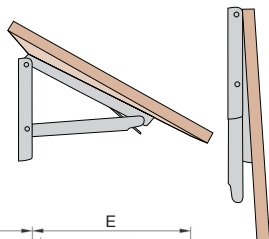

DISCOUNTS

Qty	1+	6+	20+
Disc.	Net	-5%	On request

Part N°	A	B	C	D	E	H	F	G	Admissible load (kg)	Weight (g)	Stock*	Price each 1 à 5
CPAS305-165H	307	165	29	98	156	67	38	45	150	515	✓	153,92 €
CPAS200-116H	201	116	29	155	-	-	21	80	175	332	New ✓	120,17 €

*Depending on availability - Dimensions in mm

Our other products



BLH70

Right angled gearbox,
from 26 to 128 Nm



HBM

Adjustment bushing for half-rail guide,
Adjustment bushing



RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



INS

Self tapping steel insert, Steel



EIM

Stainless steel U bolt,
Stainless steel



PRF_SDD_1820

Support for Ø18 or Ø20mm Prox detector, Ø18 and Ø20




SVT5

Screwjack with travelling screw, with translating screw



UGPC

 Actuator guide kit,
Short bearing




PRL

Wear strip for slat top chain, L profile to be



GMK17_BR

Clamp for guiding profile, Rounded only

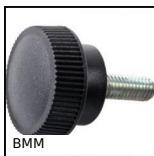

BMM

Knurled knob - male, Knurled

Complementary products



CPAS

Stay with safety catch, Opens upward