



Stainless steel folding bracket

For heavy loads



CPAS

- **Folding bracket**
- Automatic locking when in the open position
- Opening sens to the top
- Unlocking lever
- Materials:



Stainless steel 304 polished finish

Advantage

- Angle bracket with integrated hinge function

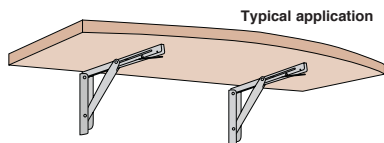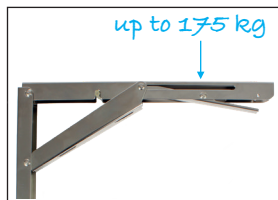

Typical application

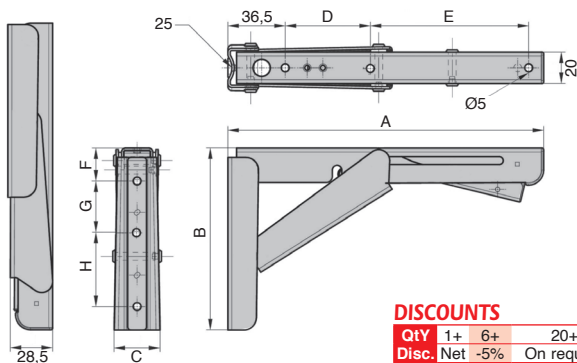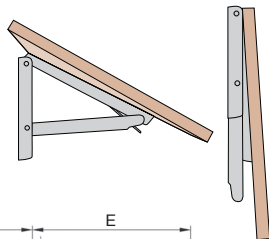

DISCOUNTS

Qty	1+	6+	20+
Disc.	Net	-5%	On request

Part N°	A	B	C	D	E	H	F	G	Admissible load (kg)	Weight (g)	Stock*	Price each 1 à 5
CPAS305-165H	307	165	29	98	156	67	38	45	150	515	✓	153,92 €
CPAS200-116H	201	116	29	155	-	-	21	80	175	332	New ✓	120,17 €

*Depending on availability - Dimensions in mm

Our other products



PW_PWG1
Wheel - precision range, Bronze



PRS50
Stainless steel articulated foot Ø50, Ø 50



T5-16ECO
T type timing pulley, Economy range - T5 aluminium



CHAR
Spring hinge, screwed



PMB
Anti-vibration machine mount, Oval base plate



CHTRB
Single and dual output gearboxes, Up to 53,1 Nm



PFM
Fixed levelling foot, Flanged plate




CHAC4040NP
Square hinge with riveted pin, not drilled, Square with riveted pin,...



WSS
Symmetrical S shaped hook, Steel



 AT5-BAR
AT type tooth bar stock, AT5



TR
Spur round rack, Stainless steel - module 0,25-1,5



T10courroie
T type timing belt, T10 Steel cored polyurethane

Complementary products



CPAS
Stay with safety catch, Opens upward