



Stainless steel folding bracket

For heavy loads



CPAS

- **Folding bracket**
- Automatic locking when in the open position
- Opening sens to the top
- Unlocking lever
- Materials:



Stainless steel 304 polished finish

Advantage

- Angle bracket with integrated hinge function

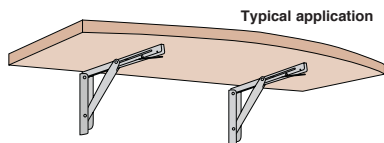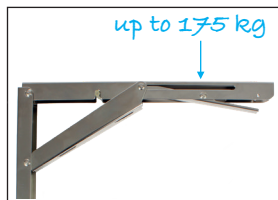

Typical application

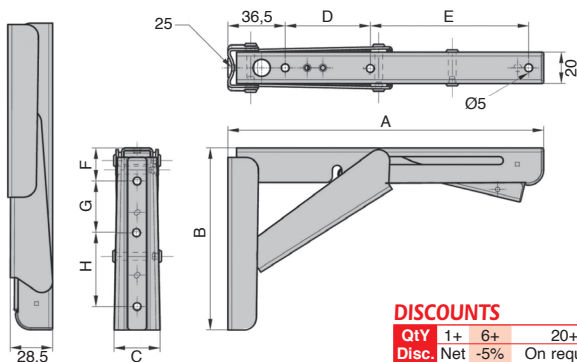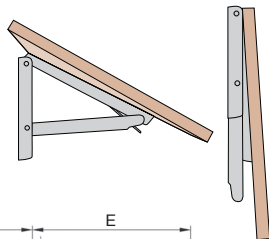

DISCOUNTS

Qty	1+	6+	20+
Disc.	Net	-5%	On request

Part N°	A	B	C	D	E	H	F	G	Admissible load (kg)	Weight (g)	Stock*	Price each 1 à 5
CPAS305-165H	307	165	29	98	156	67	38	45	150	515	✓	153,92 €
CPAS200-116H	201	116	29	155	-	-	21	80	175	332	New ✓	120,17 €

*Depending on availability - Dimensions in mm

Our other products




GSI_A

Gas control screw for gas spring, Gas control screw



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125

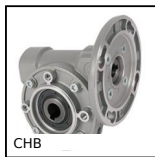

CHB

Worm and wheel gear reducer, up to 22 Nm



GCA

Linch pin, Linch



FF30

Offset spur gear reducer, from 21.50 to 83 Nm



PTMC

Telescopic furniture foot, square plate



ALIDRP240

24V DC power supply, 10 A



BPL

Ball transfer unit light duty, Light



GCH

Linear ball slide - Stainless steel balls,



G3-ECO

Eco range Spur gear, Steel C45



RLXAC8

Free roller, Steel



VTH

Hexagonal headed bolts, Steel class 8.8

Complementary products



CPAS

Stay with safety catch, Opens upward