

Stay with safety catch

Stock **Sta**


CPAS

For keeping a lid open

- **Support stay**
- Works in compression
- Opens upwards
- **Material**
Stainless steel 304, natural finish

Uses

- To close, open the lid in order to release the safety catch and then push the joint

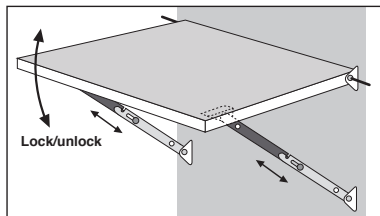


Typical application



Unlock



Lock

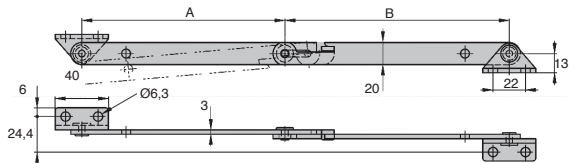

CPAS139-151-D



CPAS139-151-G

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List -5%	-10%	On request	

Part number	A	B	Weight (g)	Stock*	Price each 1 to 5
CPAS139-151-D	139	151	148	✓	30,39 €
CPAS139-151-G	139	151	148	✓	30,39 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tel. +33(0)4 37 496 496

Our other products



E60B

Right angle helical reducers, from 4.50 to 24 Nm



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80




M1

Worm and wheel set, Non hardened steel



CAP821

 Slat top chain acetal, Large range 821



QN

Single row cylindrical roller bearing, Free outer ring



J64

Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - In-line



ACLALF

Adjustable foot for aluminium profile, Ideal for workstations



CHA_GC_14SS

Stainless steel garnet hinge, To screw



SDC

Positioning sleeve for indexing pin, For pin



SHA

Handwheel without handle, Polyamide



LRX

Linear roller slide, Chariot - from 9410 N



MHWC

Double-disc flexible coupling, Double disk

Complementary products



GSI

Stainless steel gas spring, Stainless steel



CPAS-H

Folding bracket, For heavy loads