



# Eye hook with latch **high resistance**

High strenght alloy steel

**CRLHR**

- Rigging equipment
- Material:  
High strenght alloy steel red painted

## Stamping


- ØM, CE, WLL, manufacturer

## Info

- The Breaking load is calculated by multiplying the WLL by a safety factor of 4"

High strenght

Heavy loads

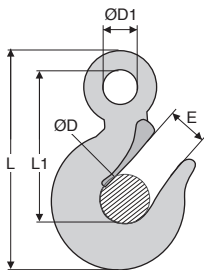

## DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-20%	On request

Part number	WLL (kg)	ØD1	ØD	L	L1	E	Weight (kg)	Stock*	Price each 1 to 5
CRL19-1000/HR	1000	19	26	111	79	18	0,300		
CRL22-1500/HR	1500	22	31	125,7	90	22,5	0,422		
CRL27-2000/HR	2000	27	33,5	142	102	24	0,660		
CRL31-3000/HR	3000	31	40	162,5	118,5	29	0,780		
CRL39-5000/HR	5000	39	48	200	146	32	1,650		
CRL50-7000/HR	7000	50	59	257	171	40	3,130		
CRL61-11000/HR	11000	61	68,5	315	228	48	5,370		

\*Dimensions in mm

 
## Our other products



SLV  
Vertical toggle clamp,  
Vertical Lever Clamp -  
steel



RBN  
Wheel, Rubber tyre -  
Polypropylene rim



GMC  
Flat profile - Round  
guide, Flat profile -  
round guide



HW\_HT  
Half-rail guide, Wheel



SCH  
Horizontal hook  
toggle clamp,  
Horizontal Hook  
clamp - stainless steel



APBC  
Circular rod, Round  
rod



AT10-32ECO  
AT type timing pulley,  
Economy range -  
AT10 aluminium



CMM\_SS  
Male rod ends DIN  
ISO12240-4, Stainless  
steel / bronze -  
Economy range



RTE  
Rotex®, jaw coupling,  
steel



PLC\_PLT  
Magnetic stud with  
central hole, With



CHINV  
Invisible hinge,  
Invisible - Opening up



WSS  
Symmetrical S shaped  
hook, Steel

## Complementary products



ADL  
Eye bolt high  
resistance, alloy steel



ADL  
Female eye bolt high  
resistance, alloy steel



PPS  
Lifting ring, Universal  
threaded



VLBG  
Lifting ring, Rotating