

# Moulded nylon rack



## Module 0.5-4.0


Nylon 6 reinforced with  
30% glass fibre

- Spur rack
- Moulded part
- Pressure angle 20°
- Material:  
Nylon 6 reinforced with  
30% glass fibre


### Info.

- The CRM1-350, CRM1,5-500 and CRM2-500 can be mounted end to end

*Racks with  
modules 1 to 4  
have steel centres*

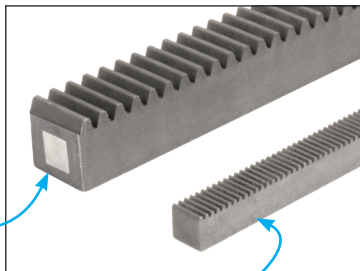

*Module 0.5  
without steel centre*

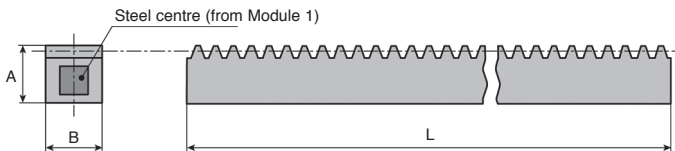

### DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-10%	-15%	On request

Part number	m Module	A	B	Length L (mm)	Stock*	Price each 1 to 5
<b>Without steel centre</b>						
CRM0.5-250	0,5	8	8	250	✓	5,43 €
<b>With steel centre</b>						
CRM1-350	1	15	15	351,67		
CRM1,5-500	1,5	17	17	565,2	✓	16,67 €
CRM2-500	2,0	20	20	565,2	✓	21,87 €
CRM3-250	3,0	30	30	250	✓	11,62 €
CRM3-500	3,0	30	30	500	✓	28,43 €
CRM3-1000	3,0	30	30	1000	✓	48,47 €
CRM4-1000	4,0	28	20	1000	-	50,54 €

\*Depending on availability - Dimensions in mm

## Our other products




PPF

Indexing plunger with flange, with drilled flange



ACL-FPA

Panel mounting block for aluminium structures, Angular connector

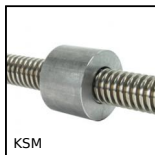

KSM

Cylindrical steel nut, Steel - 1 thread



FF10

Offset spur gear reducer, from 0.78 to 3.70 Nm



PENC

Recessed handle, clip-in



PITAss

Locking bolt, with T handle



DER80

Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW



PSG2

Spur gear - precision range, Pre-hardened Steel 35NCD6



MO

Worm and wheel set, Machined plastic (delrin)



PM3

Worm and wheel set, Hardened steel



BOX-WM

Box set of washer - DIN125, Box set of steel washers



PRF4545\_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm

## Complementary products



CRM

Moulded nylon rack, Nylon