

Moulded nylon rack



Module 0.5-4.0


Nylon 6 reinforced with 30% glass fibre

- Spur rack
- Moulded part
- Pressure angle 20°
- Material:
Nylon 6 reinforced with
30% glass fibre


Info.

- The CRM1-350, CRM1,5-500 and CRM2-500 can be mounted end to end

*Racks with
modules 1 to 4
have steel centres*

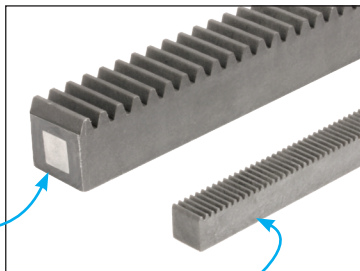

*Module 0.5
without steel centre*

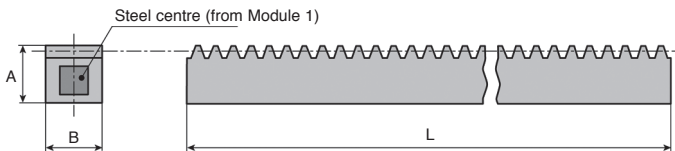

DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-10%	-15%	On request

Part number	m Module	A	B	Length L (mm)	Stock*	Price each 1 to 5
Without steel centre						
CRM0.5-250	0,5	8	8	250	✓	5,43 €
With steel centre						
CRM1-350	1	15	15	351,67		
CRM1,5-500	1,5	17	17	565,2	✓	16,67 €
CRM2-500	2,0	20	20	565,2	✓	21,87 €
CRM3-250	3,0	30	30	250	✓	11,62 €
CRM3-500	3,0	30	30	500	✓	28,43 €
CRM3-1000	3,0	30	30	1000	✓	48,47 €
CRM4-1000	4,0	28	20	1000	-	50,54 €

 
*Depending on availability - Dimensions in mm

Our other products



AT5P_AT10P

Connecting plate for AT type timing belts, AT5



M1

Worm and wheel set, Bronze



VHEH

Hexagonal headed screw with collar Hygienic Usit®, Stainless steel



ZB

Shaft for linear guides, Hardened ground stainless steel



TPEpbd

Castor for aluminium profile, Swivel with brake



GMK17 BROSSSE

Brush strip, Cone-shaped - brush



LR

Precision locknut, Precision locknut



RAM35

Manual bevel gearbox, Bevel



CTZYSS

Stainless steel diabol shaped elasto mount, Stainless steel



SHW

Plain washer, A2 Stainless steel



D-PAR_SS

 
Stainless steel progressive stop, stainless steel



T39_T49

Extension spring in metre length steel, by the metre

Complementary products



CRM

Moulded nylon rack, Nylon



ZG1

Plastic spur gear, Machined plastic (delrin)



CLG2

Moulded plastic spur gear, Moulded plastic (nylon)



ZG2

Plastic spur gear, Machined plastic (delrin)