

# Moulded nylon rack



## Module 0.5-4.0


Nylon 6 reinforced with  
30% glass fibre

- Spur rack
- Moulded part
- Pressure angle 20°
- Material:  
Nylon 6 reinforced with  
30% glass fibre


### Info.

- The CRM1-350, CRM1,5-500 and CRM2-500 can be mounted end to end

*Racks with  
modules 1 to 4  
have steel centres*

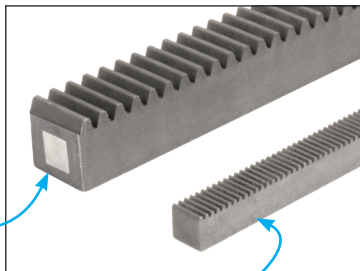

*Module 0.5  
without steel centre*

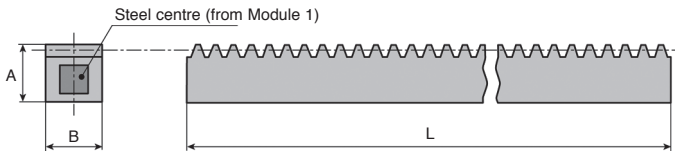

Steel centre (from Module 1)

### DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-10%	-15%	On request

Part number	m Module	A	B	Length L (mm)	Stock*	Price each 1 to 5
<b>Without steel centre</b>						
CRM0.5-250	0,5	8	8	250	✓	5,43 €
<b>With steel centre</b>						
CRM1-350	1	15	15	351,67		
CRM1,5-500	1,5	17	17	565,2	✓	16,67 €
CRM2-500	2,0	20	20	565,2	✓	21,87 €
CRM3-250	3,0	30	30	250	✓	11,62 €
CRM3-500	3,0	30	30	500	✓	28,43 €
CRM3-1000	3,0	30	30	1000	✓	48,47 €
CRM4-1000	4,0	28	20	1000	-	50,54 €

\*Depending on availability - Dimensions in mm

## Our other products



CDP  
Flanged drill bushing,  
Steel



DOMI80  
Connecting kits, XZ  
linking kit



GALRUB  
60mm rubber wheel  
for conveyor belt,  
Rubber



CTss  
Universal joint,  
telescopic, Inox, Light  
duty



DBL821  
Idler for slat top  
chain, Range 821



VEL  
Self-gripping cable  
strip, electric and  
pneumatic cables



RURp  
Swivel castor with  
double brake,  
Polyurethane -  
Aluminium rim (Free



CHMX\_CHMDX  
Shaft for worm and  
wheel reducer CHMR  
and CHM, CHMR and  
CHM gearbox...



M0  
Worm and wheel set,  
Hardened steel



PRF\_RR  
Coupling bar for  
aluminium profile,  
Coupling bar




M0  
Worm and wheel set,  
Machined plastic  
(delrin)



PSG125S  
Spur gear - precision  
range, Stainless steel  
303
 
## Complementary products



CRM  
Moulded nylon rack,  
Nylon