

Diabolo-shaped elasto mount

Ste Stock


CT-ZY

Female / female mounting


- **Radial elasticity greater than axial elasticity**
- Cylinder worked under compression or shearing
- **Materials:**
 - core: Steel plates
 - cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- **Working temp: -40°C to +70°C**

Uses

- *Dampens sound and vibrations*

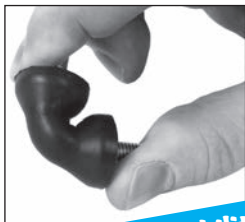

High flexibility

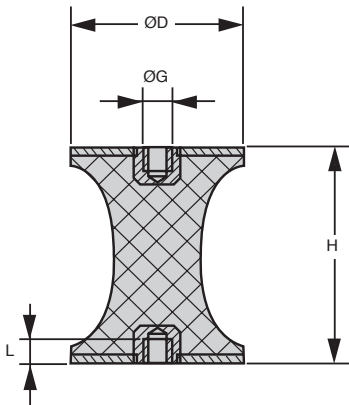

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc. List	-10%	-15%	-20%	-25%	On request	

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10	M4	10	10	4	✓	1,85 €
CT-ZY8-30-20	M8	30	20	8	✓	5,45 €
CT-ZY8-40-48	M8	40	48	8	✓	10,98 €
CT-ZY10-50-30	M10	50	30	10	-	19,25 €

*Depending on availability - Dimensions in mm

Our other products



Slat top chain acetal,
Large range 821



Lifting ring, Universal
threaded



Rubber latch clamp
with strike plate,
Lockable



Invisible hinge,
Invisible - 90° opening




Sealing washer
Hygienic Usit®,
Stainless steel - Black
EPDM



Miniature motorised
actuator 2A, 2 amperes




Speed controller 5A, 5
A

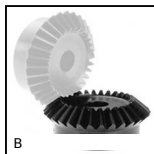

Steel bevel gear, 1:1



 Motor-gearbox 12V
and 24V DC, from



Worm and wheel gear
reducer, up to 164



Spring hinge,
screwed/welded



Worm and wheel gear
reducer, up to 73 Nm

Complementary products



Diabolo shaped elasto
mount, Steel



Stainless steel diabolo
shaped elasto mount,
Stainless steel



Cylindrical elasto
mount, Steel



Stainless steel
cylindrical elasto
mount, Stainless steel