

Diabolo-shaped elasto mount

Ste Stock


CT-ZY

Female / female mounting


- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C

Uses

- Dampens sound and vibrations

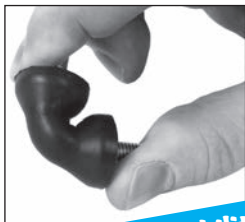

High flexibility

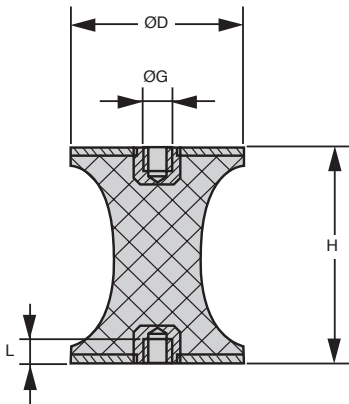

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc. List	-10%	-15%	-20%	-25%	On request	

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10	M4	10	10	4	✓	1,85 €
CT-ZY8-30-20	M8	30	20	8	✓	5,45 €
CT-ZY8-40-48	M8	40	48	8	✓	10,98 €
CT-ZY10-50-30	M10	50	30	10	-	19,25 €

*Depending on availability - Dimensions in mm

Our other products



LVT

Miniature motorised actuator 4A, 4 ampers



PRF_GAL

Roller for aluminium profile, Hollow roller ø12



 
RPCplss

Swivel castor with plate, Stainless steel - Polyamide



CHALss

Piano hinge, Stainless steel




AC

Strike for toggle latch, 18mm



PCLA_T

 Technopolymer clamping lever - male, Plastic



M0

Worm and wheel set, Machined plastic (delrin)




ZG1

Plastic spur gear, Machined plastic (delrin)




GE_ES

 Spherical bushing, Steel / steel



PM2

 Worm and wheel set, Machined plastic (delrin)



PRF-SCREEN-1

Screen support, Basic support



ETP

Modular handle for aluminium profile, Modular handle

Complementary products



ATZY

Diabolo shaped elasto mount, Steel



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



BZY

Cylindrical elasto mount, Steel



BZY_SS

Stainless steel cylindrical elasto mount, Stainless steel