

Diabolo-shaped elasto mount

Ste Stock

CT-ZY

Female / female mounting


- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
 - core: Steel plates
 - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C

Uses

- Dampens sound and vibrations



High flexibility

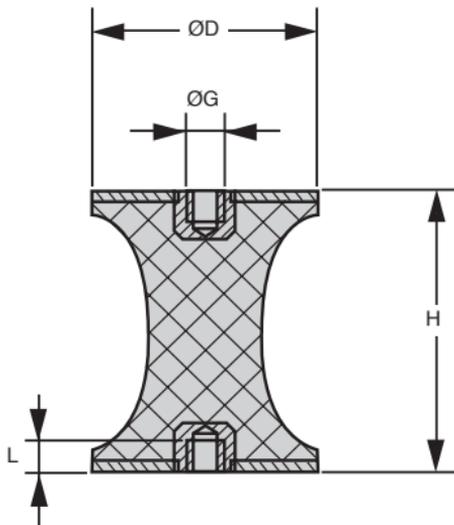

DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc. List	-10%	-15%	-20%	-25%	On request	

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10	M4	10	10	4	✓	1,85 €
CT-ZY8-30-20	M8	30	20	8	✓	5,45 €
CT-ZY8-40-48	M8	40	48	8	✓	10,98 €
CT-ZY10-50-30	M10	50	30	10	-	19,25 €

*Depending on availability - Dimensions in mm

Our other products



NCT

Square tube connector, Fixed angle



CMM_SS

Male rod ends DIN ISO12240-4, Stainless steel / bronze - Economy range



BPVM

Miniature ball transfer unit, Miniature to screw



CHM40

Worm and wheel gear reducer, up to 57 Nm



H4

Crossed helical gear crossed axis at 90°, Steel 20NCD2



VRM

Female swivelling lifting rings, Female swivelling



GDR880

Straight track for slat top chain, Ranges 880 and 881




BSM_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



CHAFR-MINI

Miniature friction hinge, Friction

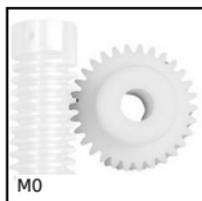

M0

Worm and wheel set, Machined plastic (delrin)



PRF_FIX_UNI

Universal fastener for aluminium profile, Universal



SCA_SS

Stainless steel flat cable clamp, Stainless steel

Complementary products



ATZY

Diabolo shaped elasto mount, Steel



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



BZY

Cylindrical elasto mount, Steel



BZY_SS

Stainless steel cylindrical elasto mount, Stainless steel