

# Diabolo-shaped elasto mount

Ste Stock


## CT-ZY

## Female / female mounting


- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
  - core: Steel plates
  - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C

### Uses

- Dampens sound and vibrations

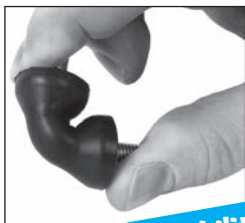

High flexibility

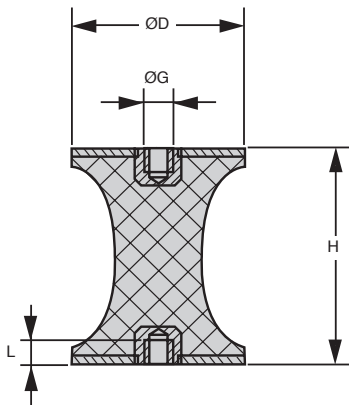

### DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc. List	-10%	-15%	-20%	-25%	On request	

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10	M4	10	10	4	✓	1,85 €
CT-ZY8-30-20	M8	30	20	8	✓	5,45 €
CT-ZY8-40-48	M8	40	48	8	✓	10,98 €
CT-ZY10-50-30	M10	50	30	10	-	19,25 €

\*Depending on availability - Dimensions in mm

## Our other products



UTKpwc

Utilitrak® 3 wheels carriage, Polymer series V wheels



SHTC

Drylin® Linear table, Maintenance free



PW\_PWG25

Worm - precision range, Stainless steel



LSAG

Precision linear rotary ball spline, Rail - from 514 N to 15386 N



PLM-20SC

Cylindrical magnet, Cylindrical magnet



VPPTss

Stainless steel handwheel with handle, Stainless steel 304



VT

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



SH1

Parallel axis helical gear, Machined plastic (delrin)



CHTRP

Single and dual output gearboxes, Up




VRBS

Folding lifting ring for welding, Folding - for



PSG25

 Spur gear - precision range, Stainless steel



B

Steel bevel gear, 1:1

## Complementary products



ATZY

Diabolo shaped elasto mount, Steel



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



BZY

Cylindrical elasto mount, Steel



BZY\_SS

Stainless steel cylindrical elasto mount, Stainless steel