

# Diabolo-shaped elasto mount

Ste Stock

## CT-ZY

## Female / female mounting


- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials:
  - core: Steel plates
  - cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C

### Uses

- Dampens sound and vibrations



High flexibility

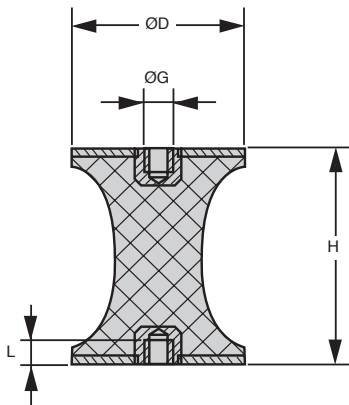

### DISCOUNTS

Qty	1+	6+	20+	40+	100+	200+
Disc. List	-10%	-15%	-20%	-25%	On request	

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10	M4	10	10	4	✓	1,85 €
CT-ZY8-30-20	M8	30	20	8	✓	5,45 €
CT-ZY8-40-48	M8	40	48	8	✓	10,98 €
CT-ZY10-50-30	M10	50	30	10	-	19,25 €

\*Depending on availability - Dimensions in mm

## Our other products




PRS30

Stainless steel articulated foot  $\varnothing 30$ ,  $\varnothing 30$



PCS62K

 Chain sprocket with hardened teeth, 15.875mm (DIN10B-1)



RPP3

RPP heavy duty timing belt, RPP3



 
H4

Crossed helical gear crossed axis at  $90^\circ$ , Steel 20NCD2



TPEpb

Castor for aluminium profile, Swivel with brake



CFC

Spring loaded position switch, Electric contact



PSG1

Spur gear - precision range, Case hardened steel 20NCD2



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



PCS50K

Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)




CHML50

Worm and wheel gear reducer, up to 107 Nm - Integrated



SLBW

 Indexing plunger, weldable, Weldable - Steel



NK80

Drylin®N miniature guiding system, Width 80mm

## Complementary products



ATZY

Diabolo shaped elasto mount, Steel



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



BZY

Cylindrical elasto mount, Steel



BZY\_SS

Stainless steel cylindrical elasto mount, Stainless steel