

# Sta Diabolo shaped stainless steel elasto mount

Female / female mounting

CT-ZYss

- Radial elasticity greater than axial elasticity
- Cylinder works under both compression and shear
- Materials :
  - Core: Stainless steel (A2)
  - Cylinder: Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

## Uses


- Dampens sound and vibrations



stainless steel



High flexibility

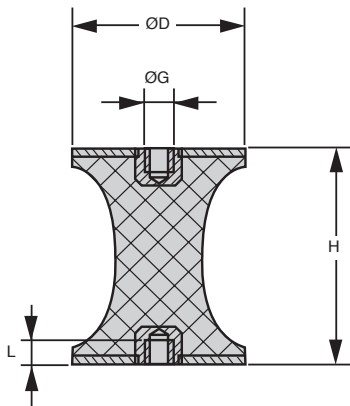

## DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10/SS	M4	10	10	4	✓	3,61 €
CT-ZY8-30-20/SS	M8	30	20	8	✓	8,17 €
CT-ZY8-40-48/SS	M8	40	48	8	✓	16,93 €
CT-ZY10-50-30/SS	M10	50	30	10	-	26,63 €

\*Depending on availability - Dimensions in mm

## Our other products



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



PWC

Powercoil thread inserts, Kit Powercoil - with or without insertion ...



PR40

Articulated foot Ø50, Ø 50



 
MDB\_MTB

Moulded plastic bevel gear (nylon), 2:1



PRF\_ECL

Nut for aluminium profile, Stainless steel square nut with tab



TPR

High helix leadscrew, Leadscrew only - up to 40mm per rotation



RVM25

Manually operated gearbox, Bevel



CHM30-MOT

Asynchronous AC motorgearboxes 0.09 to 0.22kW, 0.09 to 0.22kW



STC

Shock Absorber - stop collar, Universal flange



G0

Steel spur gear, Steel 20NCD2



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with



NK17

Drylin®N miniature guiding system, Width 17 mm

## Complementary products



CTZY

Diabolo shaped elasto mount, Steel



ATZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



AZY

Cylindrical steel elasto mount, Steel