

Sta Diabolo shaped stainless steel elasto mount

Female / female mounting

CT-ZYss


- Radial elasticity greater than axial elasticity
- Cylinder works under both compression and shear
- Materials :
 - Core: Stainless steel (A2)
 - Cylinder: Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Uses

- Dampens sound and vibrations



High flexibility

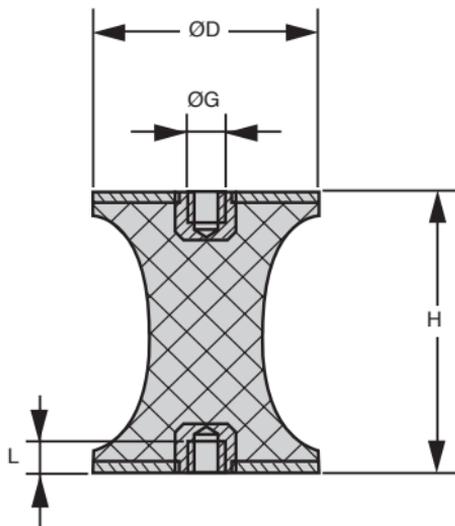


DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10/SS	M4	10	10	4	✓	3,61 €
CT-ZY8-30-20/SS	M8	30	20	8	✓	8,17 €
CT-ZY8-40-48/SS	M8	40	48	8	✓	16,93 €
CT-ZY10-50-30/SS	M10	50	30	10	-	26,63 €

*Depending on availability - Dimensions in mm

Our other products

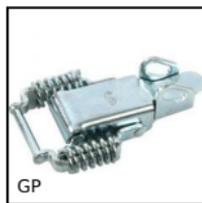

GP

Spring loaded toggle latch, With padlock-holder



RLR

Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm



DOMI50

Accessories, Clamping lever



GD01

Double universal joint, Standard duty



J52

Spur gear coaxial gearbox, from 0.27 to 0.90 Nm - In-line



GAL_20

Conveyor roller for Ø20mm spindle, Self-lubricating polyamide



WW10

Drylin® W slide, slide assembly



PRF_P

Anchor foot for 45x45 profile, Anchor foot



HLUT

Spoked handwheel with handle,



SH0

Parallel axis helical gear, Steel 20NCD2



PLB

Cylindrical spacer, Brass

Complementary products



CTZY

Diabolo shaped elasto mount, Steel



ATZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



AZY

Cylindrical elasto mount, Steel