

Sta Diabolo shaped stainless steel elasto mount

Female / female mounting

CT-ZYss


- Radial elasticity greater than axial elasticity
- Cylinder works under both compression and shear
- Materials :
 - Core: Stainless steel (A2)
 - Cylinder: Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Uses

- Dampens sound and vibrations



High flexibility

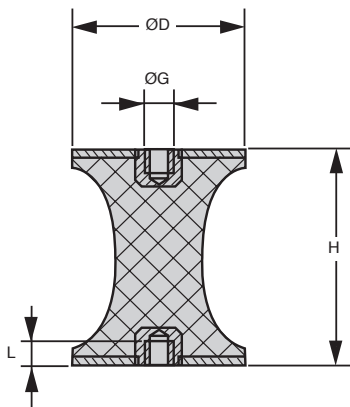

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10/SS	M4	10	10	4	✓	3,61 €
CT-ZY8-30-20/SS	M8	30	20	8	✓	8,17 €
CT-ZY8-40-48/SS	M8	40	48	8	✓	16,93 €
CT-ZY10-50-30/SS	M10	50	30	10	-	26,63 €

*Depending on availability - Dimensions in mm

Our other products



SSG1

Stainless steel spur gear, Stainless steel 304L



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



CLLCLLP

Clevis components, long version, Steel - long range



BCM_MPBT

Modular cylindrical brush, PBT polyester bristles



DOMI120

Connecting kits, XY linking kit



APB_T

Adjusting rod for clamp - Female, Bored



WJRM

Drylin® W hybrid bearing block, Hybrid bearings



LRHSS

Bi-directional leadscrew, Bi-directional - 1 thread



ACL

Joints for aluminium profiles, Variable



CLB_T

Die cast zinc clamping lever - male, Zamak



HTD5M_15

HTD Heavy duty timing pulley, HTD5



DIA

Ring operated locking bolt, with ring

Complementary products



CTZY

Diabolo shaped elasto mount, Steel



ATZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



AZY

Cylindrical elasto mount, Steel