

Sta Diabolo shaped stainless steel elasto mount

Female / female mounting

CT-ZYss

- Radial elasticity greater than axial elasticity
- Cylinder works under both compression and shear
- Materials :
 - Core: Stainless steel (A2)
 - Cylinder: Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Uses


- Dampens sound and vibrations



stainless steel



High flexibility

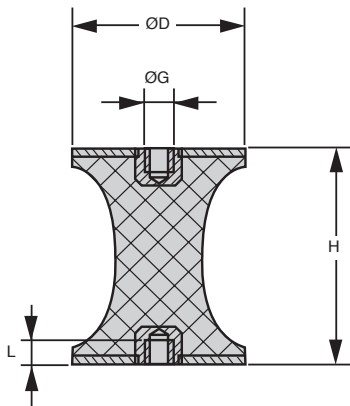

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10/SS	M4	10	10	4	✓	3,61 €
CT-ZY8-30-20/SS	M8	30	20	8	✓	8,17 €
CT-ZY8-40-48/SS	M8	40	48	8	✓	16,93 €
CT-ZY10-50-30/SS	M10	50	30	10	-	26,63 €

*Depending on availability - Dimensions in mm

Our other products



Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



Fixed levelling foot,
Flanged plate



Steel splined collar,
Steel



 
Support for Ø18 or
Ø20mm Prox
detector, Ø18 and
Ø20



Worm and wheel set,
Machined plastic
(delrin)



Diabolo shaped elasto
mount, Steel



Stainless steel thread
inserts, Stainless steel



Sheet steel flanged
bearing for light
loads, Sheet steel



Spur gear - precision
range, Pre-hardened
Steel 35NCD6



Short swivel head,
Short



Locking bolt, with T
handle



Adjustable latch
clamp with strike
plate, Stroke from
117,4mm to 128mm

Complementary products



Diabolo shaped elasto
mount, Steel



Stainless steel diabolo
shaped elasto mount,
Stainless steel



Cylindrical elasto
mount, Steel