

Sta Diabolo shaped stainless steel elasto mount

Female / female mounting

CT-ZYss

- Radial elasticity greater than axial elasticity
- Cylinder works under both compression and shear
- Materials :
 - Core: Stainless steel (A2)
 - Cylinder: Rubber
- Hardness NK55-60 Shore A
- Working temp: -40°C to +70°C

Uses


- Dampens sound and vibrations



stainless steel



High flexibility

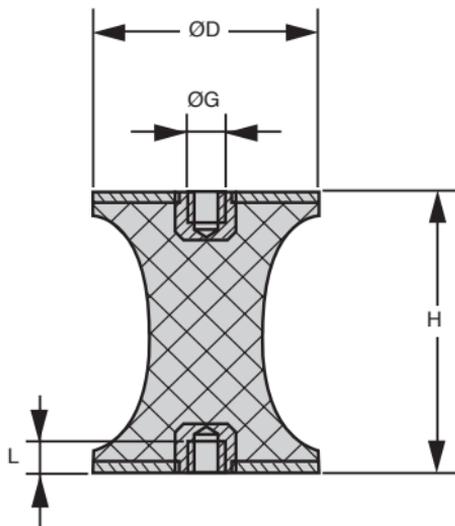

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	ØD	H	L	Stock*	Price each 1 to 5
CT-ZY4-10-10/SS	M4	10	10	4	✓	3,61 €
CT-ZY8-30-20/SS	M8	30	20	8	✓	8,17 €
CT-ZY8-40-48/SS	M8	40	48	8	✓	16,93 €
CT-ZY10-50-30/SS	M10	50	30	10	-	26,63 €

*Depending on availability - Dimensions in mm

Our other products



RTE

Rotex®, jaw coupling, steel



SBF

Sealed flange bearing unit for Food Industry, cover



BCFH

Mushroom headed button Hygienic Usit®, With male thread and high head



ADL_M

Male eye bolt conforms to DIN580, Steel



ACM_DZ

Clip for bonnet fastener, Clip



SBF

Sealed flange bearing unit for Food Industry, cover



DKGS

Backlash free coupling Gerwah®, from 0.5 to 3Nm



AF

Shaft clamp with keyway, Set screw



M2

Worm and wheel set, Hardened steel



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



PRF4590_E

Bracket for aluminium profile, PRF4590



HLA19

Right angle spiro bevel gearbox, Up to 43Nm

Complementary products



CTZY

Diabolo shaped elasto mount, Steel



ATZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



AZY

Cylindrical elasto mount, Steel