

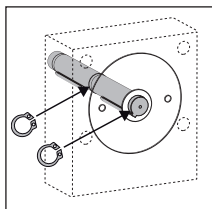


- Flexible ring for preventing axial movement of a shaft
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet

stainless steel

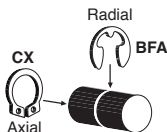

Typical application

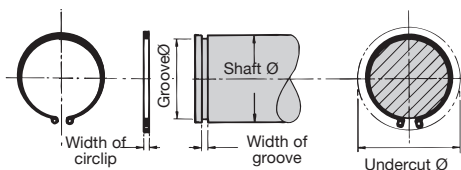

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Shaft Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CX-4S/B	4	0,40	3,80	0,50	8,60	200	✓	30,27 €
CX-5S/B	5	0,60	4,80	0,70	10,30	200	✓	28,59 €
CX-6S/B	6	0,70	5,70	0,80	11,70	200	✓	25,41 €
CX-7S/B	7	0,80	6,70	0,90	13,50	200	✓	34,34 €
CX-8S/B	8	0,80	7,60	0,90	14,70	200	✓	26,77 €
CX-9S/B	9	1,00	8,60	1,10	16,00	200	-	30,98 €
CX-10S/B	10	1,00	9,60	1,10	17,00	100	✓	16,88 €
CX-12S/B	12	1,00	11,50	1,10	19,00	100	✓	19,06 €
CX-14S/B	14	1,00	13,40	1,10	21,40	100	✓	25,66 €
CX-15S/B	15	1,00	14,30	1,10	22,60	100	✓	27,01 €
CX-16S/B	16	1,00	15,20	1,10	23,80	100	✓	29,05 €
CX-17S/B	17	1,00	16,20	1,10	25,00	100	✓	30,20 €
CX-18S/B	18	1,20	17,00	1,30	26,20	100	✓	42,34 €
CX-20S/B	20	1,20	19,00	1,30	28,40	100	✓	46,94 €
CX-22S/B	22	1,20	21,00	1,30	30,80	50	✓	42,69 €
CX-24S/B	24	1,20	22,90	1,30	33,20	50	✓	49,83 €
CX-25S/B	25	1,20	23,90	1,30	34,20	50	✓	47,69 €
CX-26S/B	26	1,20	24,90	1,30	35,50	50	✓	57,40 €
CX-30S/B	30	1,50	28,60	1,60	40,60	50	✓	63,61 €
CX-35S/B	35	1,50	33,00	1,60	47,00	25	✓	46,69 €

\*Depending on availability - Dimensions in mm

## Our other products



GE1006

Elastic ringed latch,  
Hooks into a slot



PLM-16A

Magnetic stud with  
threaded hole, With  
threaded hole



BLHB40

Right angled gearbox,  
bored shafts, up to  
10.3 Nm



CHB

Worm and wheel gear  
reducer, up to 22 Nm



CMM

Male rod ends DIN  
ISO12240-4, Steel /  
bronze



RFV63

Stainless steel worm  
and wheel gearbox,  
up to 152 Nm



PRF-SRA-78

Lock for aluminium  
profile, Quick fitting,  
self locking door lock



CHMR50

Worm and wheel gear  
reducer, up to 107  
Nm



PSG35

Spur gear - precision  
made, Stainless steel



VTLF

3 lobed handle,  
Polyamide - Brass



NTM


Nylon tipped set  
screw, Nylon-point



TB8

Cylindrical roller  
thrust bearing, Steel

## Complementary products

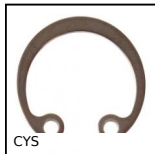

CYS

Internal circlip  
DIN472, internal DIN  
472



BFA

Shaft locking washer,  
E clip



PAL

Self locking counter  
nut, For axial locking