

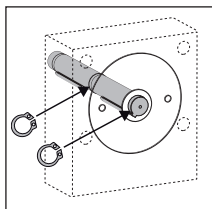


- Flexible ring for preventing axial movement of a shaft
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet

stainless steel

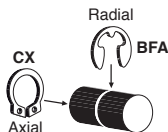

Typical application

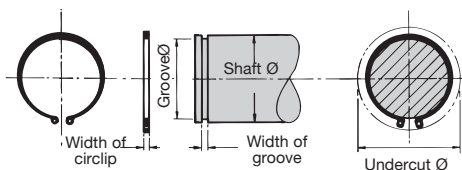

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Shaft Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CX-4S/B	4	0,40	3,80	0,50	8,60	200	✓	30,27 €
CX-5S/B	5	0,60	4,80	0,70	10,30	200	✓	28,59 €
CX-6S/B	6	0,70	5,70	0,80	11,70	200	✓	25,41 €
CX-7S/B	7	0,80	6,70	0,90	13,50	200	✓	34,34 €
CX-8S/B	8	0,80	7,60	0,90	14,70	200	✓	26,77 €
CX-9S/B	9	1,00	8,60	1,10	16,00	200	-	30,98 €
CX-10S/B	10	1,00	9,60	1,10	17,00	100	✓	16,88 €
CX-12S/B	12	1,00	11,50	1,10	19,00	100	✓	19,06 €
CX-14S/B	14	1,00	13,40	1,10	21,40	100	✓	25,66 €
CX-15S/B	15	1,00	14,30	1,10	22,60	100	✓	27,01 €
CX-16S/B	16	1,00	15,20	1,10	23,80	100	✓	29,05 €
CX-17S/B	17	1,00	16,20	1,10	25,00	100	✓	30,20 €
CX-18S/B	18	1,20	17,00	1,30	26,20	100	✓	42,34 €
CX-20S/B	20	1,20	19,00	1,30	28,40	100	✓	46,94 €
CX-22S/B	22	1,20	21,00	1,30	30,80	50	✓	42,69 €
CX-24S/B	24	1,20	22,90	1,30	33,20	50	✓	49,83 €
CX-25S/B	25	1,20	23,90	1,30	34,20	50	✓	47,69 €
CX-26S/B	26	1,20	24,90	1,30	35,50	50	✓	57,40 €
CX-30S/B	30	1,50	28,60	1,60	40,60	50	✓	63,61 €
CX-35S/B	35	1,50	33,00	1,60	47,00	25	✓	46,69 €

*Depending on availability - Dimensions in mm

Our other products



SR
Narrow spur rack,
Stainless steel



KB_WW
Closed linear
precision bearing,
Economy range



SERB
Universal latch key,
Universal latch key



DOMI30
Domino 30 adjustable
slide, Slide DOMILINE
30 with counter and
handw...



BEAB
Knob star grip
antibacterial, Star,
anti-bacterial



PTAF100-PAMF100
Articulated fixable
foot with pressed
base Ø100, Ø 100



RFV40
Stainless steel worm
and wheel gearbox,
up to 47 Nm



H1
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2




FHCSS
Countersunk screw,
Stainless steel A2 -
DIN 7991



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT10




 RVM14
Manual worm and
wheel gearbox,
Worm/wheel



RPPM
RPP type belt per
metre, RPP8 Steel
cored polyurethane

Complementary products

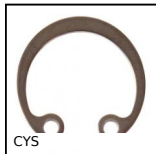

CYS
Internal circlip
DIN472, internal DIN
472



BFA
Shaft locking washer,
E clip



PAL
Self locking counter
nut, For axial locking