
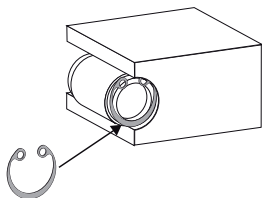


- Flexible ring for preventing axial movement of a bored component
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet, quantity depends on size

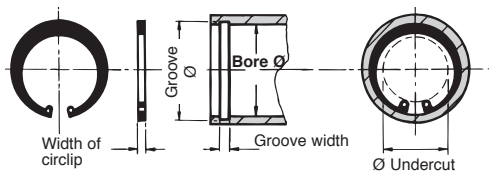

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Bore Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CY-10S/B	10	1,00	10,40	1,10	3,30	200	-	31,20 €
CY-11S/B	11	1,00	11,40	1,10	4,10	100	-	52,29 €
CY-12S/B	12	1,00	12,50	1,10	4,90	100	✓	20,45 €
CY-13S/B	13	1,00	13,60	1,10	5,40	100	-	On request
CY-14S/B	14	1,00	14,60	1,10	6,20	100	-	23,70 €
CY-15S/B	15	1,00	15,70	1,10	7,20	100	-	21,80 €
CY-16S/B	16	1,00	16,80	1,10	8,00	100	✓	22,80 €
CY-18S/B	18	1,00	19,00	1,10	9,40	100	-	25,70 €
CY-20S/B	20	1,00	21,00	1,10	11,20	100	✓	39,37 €
CY-22S/B	22	1,00	23,00	1,10	13,20	50	✓	21,91 €

*Depending on availability - Dimensions in mm

Our other products



BOX-TOR-MAX

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53



LWL

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



VMS

Stainless steel knurled thumb screw, Knurled



NK40

Drylin®N miniature guiding system, Withdh 40 mm



GG2

Ground spur gear, Heat treated steel



CHB

Single output shaft, For CHB gearbox




SH0

Parallel axis helical gear, Machined plastic (delrin)



DSF

 Slip friction clutch, 4 to 2600 Nm



AC

Strike for toggle latch, 15mm



CHB

Worm and wheel gear reducer, up to 22 Nm



PRF4545


Standard aluminium profile, 45 x 45 mm



YG3

HEAVY DUTY spur gear, Steel 35NCD6

 Complementary products



CXS

External circlip DIN471, external DIN 471



BFA

Shaft locking washer, E clip



PAL

Self locking counter nut, For axial locking