
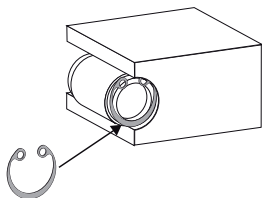


- Flexible ring for preventing axial movement of a bored component
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet, quantity depends on size

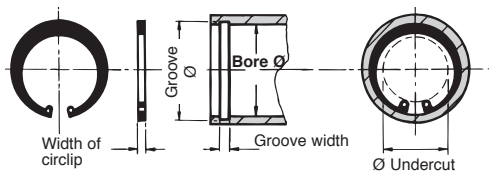

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Bore Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CY-10S/B	10	1,00	10,40	1,10	3,30	200	-	31,20 €
CY-11S/B	11	1,00	11,40	1,10	4,10	100	-	52,29 €
CY-12S/B	12	1,00	12,50	1,10	4,90	100	✓	20,45 €
CY-13S/B	13	1,00	13,60	1,10	5,40	100	-	On request
CY-14S/B	14	1,00	14,60	1,10	6,20	100	-	23,70 €
CY-15S/B	15	1,00	15,70	1,10	7,20	100	-	21,80 €
CY-16S/B	16	1,00	16,80	1,10	8,00	100	✓	22,80 €
CY-18S/B	18	1,00	19,00	1,10	9,40	100	-	25,70 €
CY-20S/B	20	1,00	21,00	1,10	11,20	100	✓	39,37 €
CY-22S/B	22	1,00	23,00	1,10	13,20	50	✓	21,91 €

*Depending on availability - Dimensions in mm

Our other products



SSB

Stainless steel bevel gear, 1:1



M1

Worm and wheel set, Non hardened steel



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



CMA

Eye bolt, Steel



PDM_PDV

Detectable plastic palm grip, blue thermoplastic



GAL22

Conveyor wheel, Zinc plated steel



PTMR

Telescopic furniture foot, threaded stud



SHW

Plain washer, Steel



KKSS

Rounded end feather key, Stainless steel



BPH

Ball transfer unit plain fit, High



PRF4545


Standard aluminium profile, 45 x 45 mm



BPVMss

Stainless steel miniature ball transfer unit, Miniature to screw

Complementary products

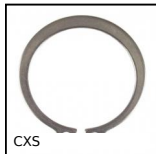

CXS

External circlip
DIN471, external DIN 471



BFA

Shaft locking washer, E clip



PAL

Self locking counter nut, For axial locking