
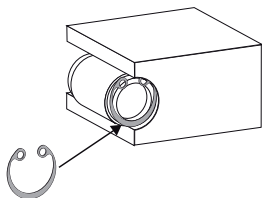


- Flexible ring for preventing axial movement of a bored component
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet, quantity depends on size

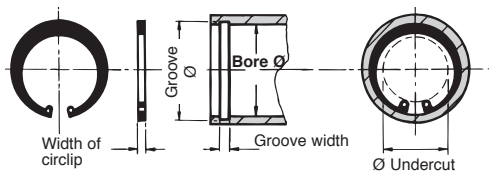

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Bore Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CY-10S/B	10	1,00	10,40	1,10	3,30	200	-	31,20 €
CY-11S/B	11	1,00	11,40	1,10	4,10	100	-	52,29 €
CY-12S/B	12	1,00	12,50	1,10	4,90	100	✓	20,45 €
CY-13S/B	13	1,00	13,60	1,10	5,40	100	-	On request
CY-14S/B	14	1,00	14,60	1,10	6,20	100	-	23,70 €
CY-15S/B	15	1,00	15,70	1,10	7,20	100	-	21,80 €
CY-16S/B	16	1,00	16,80	1,10	8,00	100	✓	22,80 €
CY-18S/B	18	1,00	19,00	1,10	9,40	100	-	25,70 €
CY-20S/B	20	1,00	21,00	1,10	11,20	100	✓	39,37 €
CY-22S/B	22	1,00	23,00	1,10	13,20	50	✓	21,91 €

\*Depending on availability - Dimensions in mm

## Our other products



BSCF

Knurled torque knobs  
- female, Knurled  
threaded torque



CHAR16046

Spring hinge, screwed



GLT3-46

Telescopic drawer,



CLLCLLP

Clevis components,  
long version, Steel -  
long version



PTRSS

Idler chain sprocket,  
For hostile  
environments



 
PSP

Support profile, Panel  
support



DB

Steel bevel gear, 2:1



PB

Plastic deep groove  
ball bearing, Plastic -  
balls material :  
stainle...



PCS8ECO

Chain sprocket - steel,  
8mm (DIN 05B-1)



CHAGC-AL

Screw-in garnet  
hinge, Screw-on



DOG111


Motor-gearbox 12V  
and 24V DC, from 1.5  
to 6 Nm



ESCON

Speed controller 5A  
accessories, USB  
cable for PC link

## Complementary products

 

CXS

External circlip  
DIN471, external DIN  
471



BFA

Shaft locking washer,  
E clip



PAL

Self locking counter  
nut, For axial locking