
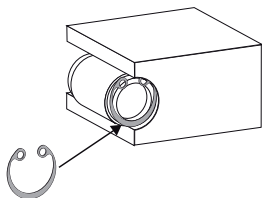


- Flexible ring for preventing axial movement of a bored component
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet, quantity depends on size

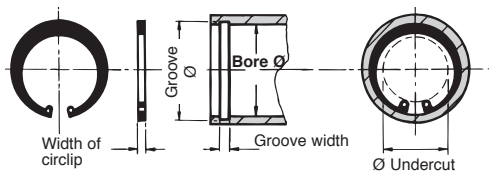

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Bore Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CY-10S/B	10	1,00	10,40	1,10	3,30	200	-	31,20 €
CY-11S/B	11	1,00	11,40	1,10	4,10	100	-	52,29 €
CY-12S/B	12	1,00	12,50	1,10	4,90	100	✓	20,45 €
CY-13S/B	13	1,00	13,60	1,10	5,40	100	-	On request
CY-14S/B	14	1,00	14,60	1,10	6,20	100	-	23,70 €
CY-15S/B	15	1,00	15,70	1,10	7,20	100	-	21,80 €
CY-16S/B	16	1,00	16,80	1,10	8,00	100	✓	22,80 €
CY-18S/B	18	1,00	19,00	1,10	9,40	100	-	25,70 €
CY-20S/B	20	1,00	21,00	1,10	11,20	100	✓	39,37 €
CY-22S/B	22	1,00	23,00	1,10	13,20	50	✓	21,91 €

\*Depending on availability - Dimensions in mm

## Our other products



BPVMss

Stainless steel miniature ball transfer unit, Miniature to screw



INS\_SS

Self tapping stainless steel insert, 316 stainless steel



GG3

Ground spur gear, Heat treated steel



GSA\_A

Adjustable gas spring, Steel



BPL

Ball transfer unit light duty, Light



BPFL

Sheet steel flanged bearing for light loads, Sheet steel



GMK17\_R

Round guide, Round guide for conical profile



BLOC

Doorstop, Doorstop



PR105

Articulated foot Ø103, Ø 103



BOXKK

Boxed set of DIN6885A keys,



T2

 
T type timing belt, T2.5 Steel cored



D-PAR\_SS

Stainless steel elastomount, stainless steel

## Complementary products



CXS

External circlip DIN471, external DIN 471



BFA

Shaft locking washer, E clip



PAL

Self locking counter nut, For axial locking