
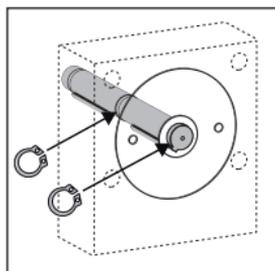


## CXs


## Shaft mounted locking ring

- Flexible ring for preventing axial movement of a shaft
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet

stainless steel

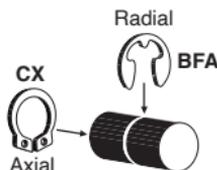

Typical application

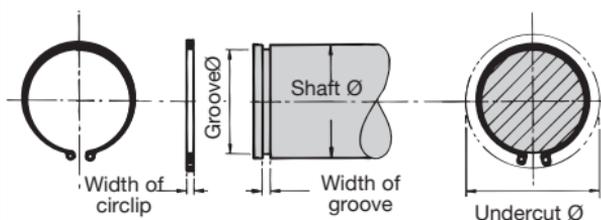



### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Shaft Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CX-4S/B	4	0,40	3,80	0,50	8,60	200	✓	31,16 €
CX-5S/B	5	0,60	4,80	0,70	10,30	200	✓	33,60 €
CX-6S/B	6	0,70	5,70	0,80	11,70	200	✓	26,16 €
CX-7S/B	7	0,80	6,70	0,90	13,50	200	✓	35,35 €
CX-8S/B	8	0,80	7,60	0,90	14,70	200	✓	27,55 €
CX-9S/B	9	1,00	8,60	1,10	16,00	200	-	31,89 €
CX-10S/B	10	1,00	9,60	1,10	17,00	100	✓	17,37 €
CX-12S/B	12	1,00	11,50	1,10	19,00	100	✓	28,95 €
CX-14S/B	14	1,00	13,40	1,10	21,40	100	✓	31,56 €
CX-15S/B	15	1,00	14,30	1,10	22,60	100	✓	35,76 €
CX-16S/B	16	1,00	15,20	1,10	23,80	100	✓	29,90 €
CX-17S/B	17	1,00	16,20	1,10	25,00	100	✓	31,08 €
CX-18S/B	18	1,20	17,00	1,30	26,20	100	✓	48,81 €
CX-20S/B	20	1,20	19,00	1,30	28,40	100	✓	57,53 €
CX-22S/B	22	1,20	21,00	1,30	30,80	50	✓	43,94 €
CX-24S/B	24	1,20	22,90	1,30	33,20	50	✓	51,29 €
CX-25S/B	25	1,20	23,90	1,30	34,20	50	✓	72,41 €
CX-26S/B	26	1,20	24,90	1,30	35,50	50	✓	59,09 €
CX-30S/B	30	1,50	28,60	1,60	40,60	50	✓	65,47 €
CX-35S/B	35	1,50	33,00	1,60	47,00	25	✓	52,42 €

\*Depending on availability - Dimensions in mm

- Flexible ring for preventing axial movement of a bored component
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet, quantity depends on size

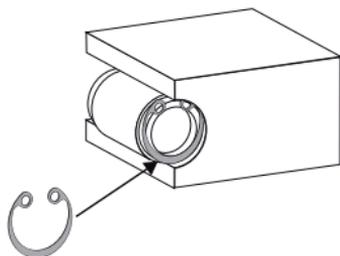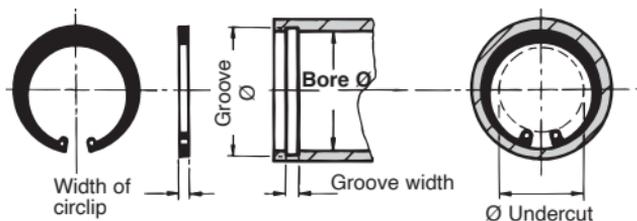

### DISCOUNTS

Qty	1+	2+	4+
Disc. List	-	-20%	On request

Part number	Bore Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CY-10S/B	10	1,00	10,40	1,10	3,30	200	-	32,11 €
CY-11S/B	11	1,00	11,40	1,10	4,10	100	-	53,82 €
CY-12S/B	12	1,00	12,50	1,10	4,90	100	✓	21,05 €
CY-13S/B	13	1,00	13,60	1,10	5,40	100	-	On request
CY-14S/B	14	1,00	14,60	1,10	6,20	100	-	24,39 €
CY-15S/B	15	1,00	15,70	1,10	7,20	100	-	27,68 €
CY-16S/B	16	1,00	16,80	1,10	8,00	100	✓	23,47 €
CY-18S/B	18	1,00	19,00	1,10	9,40	100	-	26,45 €
CY-20S/B	20	1,00	21,00	1,10	11,20	100	✓	40,52 €
CY-22S/B	22	1,00	23,00	1,10	13,20	50	✓	22,55 €

\*Depending on availability - Dimensions in mm