
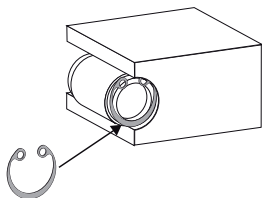


- Flexible ring for preventing axial movement of a bored component
- Special pliers required for mounting (not supplied)
- Material: Stainless steel A2
- Corrosion resistant
- Working temperature: -20°C to +200°C (300°C occasionally)
- Sold by the packet, quantity depends on size

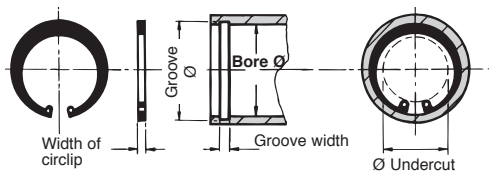

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Bore Ø	Circlip width	Groove Ø	Groove width	Undercut Ø	Qty. per packet	Stock*	Price per packet
CY-10S/B	10	1,00	10,40	1,10	3,30	200	-	31,20 €
CY-11S/B	11	1,00	11,40	1,10	4,10	100	-	52,29 €
CY-12S/B	12	1,00	12,50	1,10	4,90	100	✓	20,45 €
CY-13S/B	13	1,00	13,60	1,10	5,40	100	-	On request
CY-14S/B	14	1,00	14,60	1,10	6,20	100	-	23,70 €
CY-15S/B	15	1,00	15,70	1,10	7,20	100	-	21,80 €
CY-16S/B	16	1,00	16,80	1,10	8,00	100	✓	22,80 €
CY-18S/B	18	1,00	19,00	1,10	9,40	100	-	25,70 €
CY-20S/B	20	1,00	21,00	1,10	11,20	100	✓	39,37 €
CY-22S/B	22	1,00	23,00	1,10	13,20	50	✓	21,91 €

*Depending on availability - Dimensions in mm

Our other products




RVM14
Manual worm and
wheel gearbox,
Worm/wheel



RJA00_02
Sealing strip, Clipping



PTA80ssEB
Articulated foot with
sheet metal base
Ø80, Articulated foot

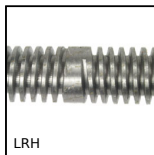

LRH
Bi-directional
leadscrew, Bi-
directional - 1 thread



PRF-SRA-78
Lock for aluminium
profile, Quick fitting,
self locking door lock



TBL
Mini leadscrew table
with metric thread,
For manual position
adjustm...



ACL
Joints for aluminium
profiles, Variable
angle corner



AFM
Flanged polymer
bush, Food grade
polymer




D-PAR_SS
Stainless steel elasto
mount, stainless steel



PRF_CH
Cable-carrier chain for
aluminium profile,




STRIP1000
Sealing brush strip,
1m length

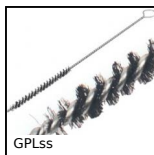

GPLss
Brush, stainless steel

 Complementary products



CXS
External circlip
DIN471, external DIN
471



BFA
Shaft locking washer,
E clip



PAL
Self locking counter
nut, For axial locking