


Male mounting

D-PARss
D-KONss


- **Very high deformation allowing high** levels of energy to be absorbed.
- Progressive deformation
- Materials :
 - Core : Stainless steel plates (A2)
 - Head : Rubber
- **Hardness : NK 55-60 Shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop
- D-KON12-80-30/SS
square base 80x80mm

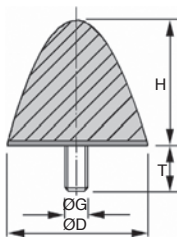

Type D-PARss

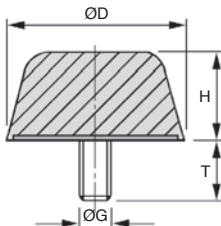

Type D-KONss

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	T	ØD	H	Stock*	Price each 1 to 5
D-PAR6-20-24/SS	M6	18	20	24	✓	3,78 €
D-PAR8-30-36/SS	M8	20	30	36	✓	5,85 €
D-PAR8-35-40/SS	M8	20	35	40	✓	15,84 €
D-PAR8-50-67/SS	M8	36	50	67	✓	16,27 €
D-PAR10-50-58/SS	M10	28	50	58	✓	12,63 €
D-KON6-25-17/SS	M6	18	25	17	✓	3,62 €
D-KON10-50-18/SS	M10	28	50	18	✓	9,09 €
D-KON12-80-30/SS	M12	35	80	30	-	48,56 €
D-KON16-125-45/SS	M16	45	125	45	-	105,56 €

*Depending on availability - Dimensions in mm

Our other products



HLA24

Right angle spiro bevel gearbox, Up to 78Nm



GE

Toggle latches, Standard




RT25

Self-centering flanged locking assembly, Medium/high torque



P55

Worm and wheel gear reducer, up to 57 Nm

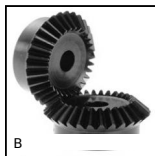

B

Steel bevel gear, 1:1



COA-COG

Surface mounting plate, Surface mounting plate for clevis



HTD14M_85

HTD Heavy duty timing pulley, HTD14 Cast



CQA30

Adjustment slide-system miniature, 30



MFB

Flexible bellows coupling, Aluminium and Bronze - With set



AFSE

Locking pin with interlocking safety latch, with



V3RA_PT

3-spoked handwheel with handle, Polyamide



SRP

Slotted spring pin ISO8752, Split ISO 8752

Complementary products



DPAK_DKON

Conical elasto buffer, Steel



D-PAR_SS

Stainless steel progressive stop, stainless steel