


Male mounting

D-PARss
D-KONss


- Very high deformation allowing high levels of energy to be absorbed.
- Progressive deformation
- Materials :
 - Core : Stainless steel plates (A2)
 - Head : Rubber
- **Hardness : NK 55-60 Shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop
- D-KON12-80-30/SS square base 80x80mm

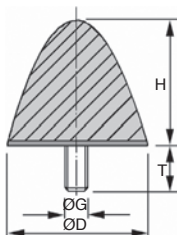

Type D-PARss

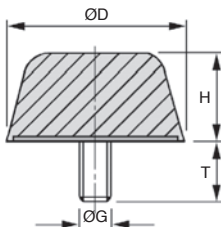

Type D-KONss


DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	T	ØD	H	Stock*	Price each 1 to 5
D-PAR6-20-24/SS	M6	18	20	24	✓	3,78 €
D-PAR8-30-36/SS	M8	20	30	36	✓	5,85 €
D-PAR8-35-40/SS	M8	20	35	40	✓	15,84 €
D-PAR8-50-67/SS	M8	36	50	67	✓	16,27 €
D-PAR10-50-58/SS	M10	28	50	58	✓	12,63 €
D-KON6-25-17/SS	M6	18	25	17	✓	3,62 €
D-KON10-50-18/SS	M10	28	50	18	✓	9,09 €
D-KON12-80-30/SS	M12	35	80	30	-	48,56 €
D-KON16-125-45/SS	M16	45	125	45	-	105,56 €

*Depending on availability - Dimensions in mm

 Our other products



Worm and wheel set,
Machined plastic
(delrin)



 
SF_ZZ

Deep groove ball
bearing, Stainless
steel



HLUss

Spoked handwheel,
Stainless steel 316



CF

Cam follower,
Standard - steel



GP75

Spring loaded toggle
latch, Standard
(GP75)



BAC105

Storage bin, 8mm



PLS

Cylindrical spacer,
Stainless steel 303



ZBconique

Machined plastic
bevel gear, 1:1



M0

Worm and wheel set,
Hardened steel



BABpss

301 Stainless steel
ball pin, Stainless
steel



RFK48C

Hypoid gearbox -
Stainless steel, up to
350 Nm



GE32

Sprung toggle latch
with connecting link,
Standard

Complementary products



DPAR_DKON

Conical elasto buffer,
Steel



D-PAR_SS

Stainless steel
progressive stop,
stainless steel