


Male mounting

D-PARss
D-KONss


- Very high deformation allowing high levels of energy to be absorbed.
- Progressive deformation
- Materials :
 - Core : Stainless steel plates (A2)
 - Head : Rubber
- **Hardness : NK 55-60 Shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop
- D-KON12-80-30/SS
square base 80x80mm

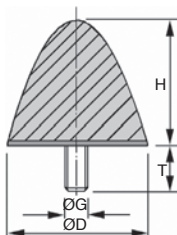

Type D-PARss

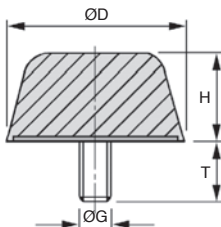

Type D-KONss

DISCOUNTS

Qty	1+	6+	20+	40+	100+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØG	T	ØD	H	Stock*	Price each 1 to 5
D-PAR6-20-24/SS	M6	18	20	24	✓	3,78 €
D-PAR8-30-36/SS	M8	20	30	36	✓	5,85 €
D-PAR8-35-40/SS	M8	20	35	40	✓	15,84 €
D-PAR8-50-67/SS	M8	36	50	67	✓	16,27 €
D-PAR10-50-58/SS	M10	28	50	58	✓	12,63 €
D-KON6-25-17/SS	M6	18	25	17	✓	3,62 €
D-KON10-50-18/SS	M10	28	50	18	✓	9,09 €
D-KON12-80-30/SS	M12	35	80	30	-	48,56 €
D-KON16-125-45/SS	M16	45	125	45	-	105,56 €

*Depending on availability - Dimensions in mm

Our other products



CLB_T

Die cast zinc clamping lever - male, Zamak



CHMR30

Worm and wheel gear reducer, up to 28 Nm



HSS

Shoulder screw ISO7379, Hardened Steel class 12.9



DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



VRSF

Male swivelling lifting ring, Male swivelling



 
TIF

Threaded rod - DIN975, Stainless steel A2



HS

Hexagonal spacer, Stainless steel 303



AC

Strike for toggle latch, 18mm



RURp

Swivel castor with double brake,



DKONSL

Silicone conical elasto buffer, Male mounting



ADL_M

Male eye bolt conforms to DIN580,



PR40

Articulated foot Ø50, Ø 50

Complementary products



DPAR_DKON

Conical elasto buffer, Steel



D-PAR_SS

Stainless steel elasto mount, stainless steel



DKONSL

Silicone conical elasto buffer, Male mounting