


- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
Steel piano wire
In accordance with DIN 17223
Class C. No 1,1200
Stainless steel in accordance with
DIN 17224 No 1,4310
(Stainless steel 302 AMS)

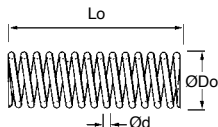

DISCOUNTS

Qty	1+	6+	+10
Disc.	List	-10%	On request

Part number		Outside Ø	Wire Ø	Free length	Max. load (N)		Stock*		Price each 1 to 5	
Steel	Stainless	Do	d	Lo	Steel	Stainless	Steel	Stainless	Steel	Stainless
D19000	D29000	2,40	0,40	1000	11,24	9,65	✓	✓	16,66 €	19,87 €
D19010	D29010	3,60	0,40	1000	4,90	4,25	-	✓	16,66 €	19,87 €
D19020	D29020	3,70	0,50	1000	18,46	10,91	✓	✓	16,66 €	19,87 €
D19030	D29030	4,50	0,50	1000	9,90	8,56	✓	✓	16,66 €	19,87 €
D19040	D29040	4,63	0,63	1000	19,30	16,57	✓	✓	16,66 €	19,87 €
D19050	D29050	5,63	0,63	1000	9,60	8,25	✓	✓	16,66 €	19,87 €
D19060	D29060	5,80	0,80	1000	29,20	25,04	✓	✓	17,38 €	19,87 €
D19070	D29070	7,10	0,80	1000	14,10	12,41	✓	✓	17,38 €	19,87 €
D19080	D29080	7,30	1,00	1000	34,20	29,34	✓	✓	17,38 €	21,40 €
D19090	D29090	9,00	1,00	1000	30,00	22,24	✓	✓	17,38 €	21,40 €
D19100	D29100	9,25	1,25	1000	85,00	72,99	✓	✓	17,38 €	22,36 €
D19110	D29110	11,25	1,25	1000	57,30	49,19	✓	✓	17,38 €	22,36 €
D19120	D29120	11,60	1,60	1000	129,60	111,30	✓	✓	18,66 €	24,79 €
D19130	D29130	14,10	1,60	1000	78,20	67,19	✓	✓	18,66 €	24,79 €
D19140	D29140	14,50	2,00	1000	207,00	177,80	✓	✓	19,86 €	26,83 €
D19150	D29150	18,00	2,00	1000	144,00	123,70	✓	✓	19,86 €	26,83 €
D19160	D29160	15,00	2,20	1000	166,00	142,60	-	-	21,40 €	31,72 €
D19170	D29170	24,00	2,20	1000	166,60	143,10	✓	-	21,40 €	31,72 €
D19180	D29180	18,50	2,50	1000	301,70	259,10	✓	✓	22,36 €	36,10 €
D19190	D29190	22,50	2,50	1000	200,70	172,30	✓	✓	22,36 €	36,10 €
D19200	D29200	20,00	2,80	1000	363,60	312,30	✓	-	24,79 €	42,01 €
D19210	D29210	30,00	2,80	1000	202,10	173,60	✓	✓	24,79 €	42,01 €
D19220	D29220	28,20	3,20	1000	251,70	216,20	✓	✓	26,83 €	49,66 €
D19230	D29230	35,20	3,20	1000	230,60	198,10	✓	✓	26,83 €	49,66 €

*Depending on availability - Dimensions in mm


Steel or stainless steel

T39 T49

- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
 - Steel piano wire conforming to DIN 17223 Class C No 1.1200
 - Stainless steel piano wire conforming to DIN 17224 No 1.4310 (Stainless steel 302 AMS)



steel or stainless steel

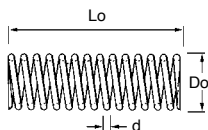

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-10%	On request

Part number	Ø	Outside Do	Wire Ø d	Free length Lo	Stock*		Price each 1 to 5	
					Steel	S/steel	Steel	S/steel
T39000	T49000	2,40	0,40	1000	✓	✓	22,36 €	26,83 €
T39010	T49010	2,90	0,40	1000	-	✓	22,36 €	26,83 €
T39020	T49020	2,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39030	T49030	4,00	0,50	1000	✓	✓	26,83 €	31,72 €
T39040	T49040	4,53	0,63	1000	✓	✓	30,17 €	34,27 €
T39050	T49050	7,03	0,63	1000	✓	✓	30,17 €	34,27 €
T39060	T49060	5,50	0,80	1000	✓	✓	31,72 €	40,69 €
T39070	T49070	9,00	0,80	1000	✓	✓	31,72 €	40,69 €
T39080	T49080	6,00	1,00	1000	⚠	✓	34,27 €	42,01 €
T39090	T49090	10,00	1,00	1000	✓	✓	34,27 €	42,01 €
T39100	T49100	7,50	1,25	1000	✓	-	38,36 €	51,11 €
T39110	T49110	13,05	1,25	1000	✓	-	38,36 €	51,11 €
T39120	T49120	11,00	1,60	1000	✓	-	40,69 €	56,24 €
T39130	T49130	17,00	1,60	1000	✓	✓	40,69 €	56,24 €
T39140	T49140	14,00	2,00	1000	✓	-	42,01 €	136,00 €
T39150	T49150	22,00	2,00	1000	✓	-	42,01 €	136,00 €
T39160	T49160	15,00	2,20	1000	✓	-	46,80 €	88,19 €
T39170	T49170	24,00	2,20	1000	⚠	-	46,80 €	88,19 €
T39180	T49180	18,00	2,50	1000	✓	✓	49,66 €	103,81 €
T39190	T49190	28,00	2,50	1000	-	-	49,66 €	103,81 €
T39200	T49200	20,00	2,80	1000	✓	-	53,51 €	122,08 €
T39210	T49210	30,00	2,80	1000	✓	-	53,51 €	122,08 €
T39220	T49220	22,00	3,20	1000	-	-	56,24 €	202,14 €
T39230	T49230	36,00	3,20	1000	✓	-	56,24 €	202,14 €

*Depending on availability - Dimensions in mm