


D19-D29 Steel or stainless steel piano wire Ø0,4-Ø3,2

- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
Steel piano wire
In accordance with DIN 17223
Class C. No 1,1200
Stainless steel in accordance with
DIN 17224 No 1,4310
(Stainless steel 302 AMS)

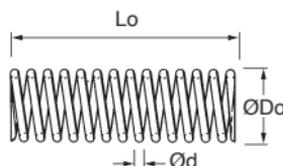

DISCOUNTS

Qty	1+	6+	+10
Disc.	List -10%	On request	

Part number		Outside Ø Wire Ø		Free length Lo	Max. load (N)		Stock*		Price each 1 to 5	
Steel	Stainless	Do	d		Steel	Stainless	Steel	Stainless	Steel	Stainless
D19000	D29000	2,40	0,40	1000	11,24	9,65	✓	✓	30,87 €	32,72 €
D19010	D29010	3,60	0,40	1000	4,90	4,25	-	✓	30,87 €	32,72 €
D19020	D29020	3,70	0,50	1000	18,46	10,91	✓	✓	30,87 €	32,72 €
D19030	D29030	4,50	0,50	1000	9,90	8,56	✓	✓	30,87 €	32,72 €
D19040	D29040	4,63	0,63	1000	19,30	16,57	✓	✓	30,87 €	32,72 €
D19050	D29050	5,63	0,63	1000	9,60	8,25	✓	✓	30,87 €	32,72 €
D19060	D29060	5,80	0,80	1000	29,20	25,04	✓	✓	32,21 €	34,77 €
D19070	D29070	7,10	0,80	1000	14,10	12,41	✓	✓	32,21 €	34,77 €
D19080	D29080	7,30	1,00	1000	34,20	29,34	✓	✓	31,31 €	34,14 €
D19090	D29090	9,00	1,00	1000	30,00	22,24	✓	✓	31,31 €	34,14 €
D19100	D29100	9,25	1,25	1000	85,00	72,99	✓	✓	32,21 €	34,52 €
D19110	D29110	11,25	1,25	1000	57,30	49,19	✓	✓	32,21 €	34,52 €
D19120	D29120	11,60	1,60	1000	129,60	111,30	✓	✓	32,65 €	33,17 €
D19130	D29130	14,10	1,60	1000	78,20	67,19	✓	✓	32,65 €	33,17 €
D19140	D29140	14,50	2,00	1000	207,00	177,80	✓	✓	32,70 €	35,90 €
D19150	D29150	18,00	2,00	1000	144,00	123,70	✓	✓	32,70 €	35,90 €
D19160	D29160	15,00	2,20	1000	166,00	142,60	-	-	34,14 €	44,09 €
D19170	D29170	24,00	2,20	1000	166,60	143,10	✓	-	34,14 €	44,09 €
D19180	D29180	18,50	2,50	1000	301,70	259,10	✓	✓	34,52 €	50,16 €
D19190	D29190	22,50	2,50	1000	200,70	172,30	✓	✓	34,52 €	50,16 €
D19200	D29200	20,00	2,80	1000	363,60	312,30	✓	-	35,71 €	58,38 €
D19210	D29210	30,00	2,80	1000	202,10	173,60	✓	✓	35,71 €	58,38 €
D19220	D29220	28,20	3,20	1000	251,70	216,20	✓	✓	35,90 €	63,89 €
D19230	D29230	35,20	3,20	1000	230,60	198,10	✓	✓	35,90 €	63,89 €


*Depending on availability - Dimensions in mm

SteSta Stock Extension spring by the metre


Steel or stainless steel piano wire

T39-T49
Ø0,4-Ø3,2

- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
 - Steel piano wire conforming to DIN 17223 Class C No 1.1200
 - Stainless steel piano wire conforming to DIN 17224 No 1.4310 (Stainless steel 302 AMS)

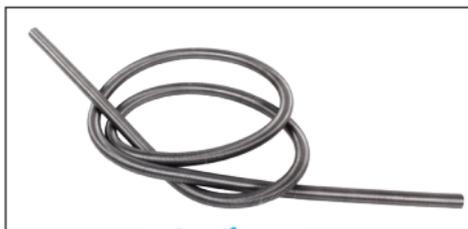

steel or stainless steel

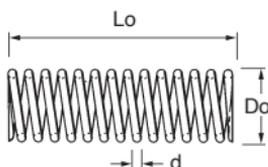

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-10%	On request

Part number	Ø	Outside	Wire Ø	Free length	Stock*		Price each 1 to 5	
					Steel	S/steel	Steel	S/steel
T39000	T49000	2,40	0,40	1000	✓	✓	35,67 €	35,90 €
T39010	T49010	3,40	0,40	1000	-	✓	35,67 €	35,90 €
T39020	T49020	3,50	0,50	1000	✓	✓	37,28 €	40,81 €
T39030	T49030	5,50	0,50	1000	✓	✓	37,28 €	40,81 €
T39040	T49040	4,53	0,63	1000	✓	✓	40,37 €	44,10 €
T39050	T49050	7,03	0,63	1000	✓	✓	40,37 €	44,10 €
T39060	T49060	5,50	0,80	1000	-	✓	40,81 €	50,26 €
T39070	T49070	9,00	0,80	1000	✓	✓	40,81 €	50,26 €
T39080	T49080	7,00	1,00	1000	-	✓	44,10 €	51,89 €
T39090	T49090	11,00	1,00	1000	✓	✓	44,10 €	51,89 €
T39100	T49100	8,55	1,25	1000	✓	-	49,36 €	63,13 €
T39110	T49110	13,05	1,25	1000	✓	-	49,36 €	63,13 €
T39120	T49120	11,00	1,60	1000	✓	-	52,36 €	63,68 €
T39130	T49130	17,00	1,60	1000	✓	✓	52,36 €	63,68 €
T39140	T49140	14,00	2,00	1000	✓	-	54,06 €	69,99 €
T39150	T49150	22,00	2,00	1000	✓	-	54,06 €	69,99 €
T39160	T49160	15,00	2,20	1000	✓	-	60,22 €	68,08 €
T39170	T49170	24,00	2,20	1000	-	-	60,22 €	68,08 €
T39180	T49180	18,00	2,50	1000	✓	✓	63,89 €	74,79 €
T39190	T49190	28,00	2,50	1000	-	-	63,89 €	74,79 €
T39200	T49200	20,00	2,80	1000	✓	-	68,84 €	75,40 €
T39210	T49210	30,00	2,80	1000	✓	-	68,84 €	75,40 €
T39220	T49220	22,00	3,20	1000	-	-	72,37 €	83,22 €
T39230	T49230	36,00	3,20	1000	✓	-	72,37 €	83,22 €

* Depending on availability - Dimensions in mm