


- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
Steel piano wire
In accordance with DIN 17223
Class C. No 1,1200
Stainless steel in accordance with
DIN 17224 No 1,4310
(Stainless steel 302 AMS)

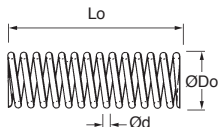

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number		Outside Ø Wire Ø		Free length	Max. load (N)		Stock*		Price each 1 to 5	
Steel	Stainless	Do	d		Steel	Stainless	Steel	Stainless	Steel	Stainless
D19000	D29000	2,40	0,40	1000	11,24	9,65	✓	✓	16,66 €	19,87 €
D19010	D29010	3,60	0,40	1000	4,90	4,25	-	✓	16,66 €	19,87 €
D19020	D29020	3,70	0,50	1000	18,46	10,91	✓	✓	16,66 €	19,87 €
D19030	D29030	4,50	0,50	1000	9,90	8,56	✓	✓	16,66 €	19,87 €
D19040	D29040	4,63	0,63	1000	19,30	16,57	✓	✓	16,66 €	19,87 €
D19050	D29050	5,63	0,63	1000	9,60	8,25	✓	✓	16,66 €	19,87 €
D19060	D29060	5,80	0,80	1000	29,20	25,04	✓	✓	17,38 €	19,87 €
D19070	D29070	7,10	0,80	1000	14,10	12,41	✓	✓	17,38 €	19,87 €
D19080	D29080	7,30	1,00	1000	34,20	29,34	✓	✓	17,38 €	21,40 €
D19090	D29090	9,00	1,00	1000	30,00	22,24	✓	✓	17,38 €	21,40 €
D19100	D29100	9,25	1,25	1000	85,00	72,99	✓	✓	17,38 €	22,36 €
D19110	D29110	11,25	1,25	1000	57,30	49,19	✓	✓	17,38 €	22,36 €
D19120	D29120	11,60	1,60	1000	129,60	111,30	✓	✓	18,66 €	24,79 €
D19130	D29130	14,10	1,60	1000	78,20	67,19	✓	✓	18,66 €	24,79 €
D19140	D29140	14,50	2,00	1000	207,00	177,80	✓	✓	19,86 €	26,83 €
D19150	D29150	18,00	2,00	1000	144,00	123,70	✓	✓	19,86 €	26,83 €
D19160	D29160	15,00	2,20	1000	166,00	142,60	-	-	21,40 €	31,72 €
D19170	D29170	24,00	2,20	1000	166,60	143,10	✓	-	21,40 €	31,72 €
D19180	D29180	18,50	2,50	1000	301,70	259,10	✓	✓	22,36 €	36,10 €
D19190	D29190	22,50	2,50	1000	200,70	172,30	✓	✓	22,36 €	36,10 €
D19200	D29200	20,00	2,80	1000	363,60	312,30	✓	-	24,79 €	42,01 €
D19210	D29210	30,00	2,80	1000	202,10	173,60	✓	✓	24,79 €	42,01 €
D19220	D29220	28,20	3,20	1000	251,70	216,20	✓	✓	26,83 €	49,66 €
D19230	D29230	35,20	3,20	1000	230,60	198,10	✓	✓	26,83 €	49,66 €

*Depending on availability - Dimensions in mm

Our other products



VTH

Hexagonal headed bolts, Steel class 8.8



CHAsb28

Roll of hinge without pin, Plastic hinge



NKIB

Combined bearing with inner ring, Axial load in both directions



RPCtc

Swivel castor with central hole, Steel - Polyamide - with double brake



FIRSTDC1Q60

Speed controller 10A, 10 A



COA-COG

Surface mounting plate, Surface mounting plate for clevis



UTKswrr

V shaped channel UtiliTrak®, V rail



AC144

Strike for toggle latch, 22mm



M1

Worm and wheel set, Machined plastic



T10_21_AL

T type timing pulley, Economy range - T10



VTLF

3 lobed handle, Polyamide - Brass



DFG

Flat suction cup, silicon

Complementary products



D19_D29

Compression springs in metre length stainless steel, by the metre



CDGamme

Compression spring DIN2095, DIN 2095



CDC

Conical compression spring, Conical