

Ratio 2:1


Steel C43

- Module 1.5 to 5
- Teeth conform to DIN 3967 except for Module 1 models which are Gleason
- Pressure angle: 20°
- Material: steel C43
- A pair requires 2 gears



Info.

- **Pilot bore dimensions given as a guide only and are subject to change.

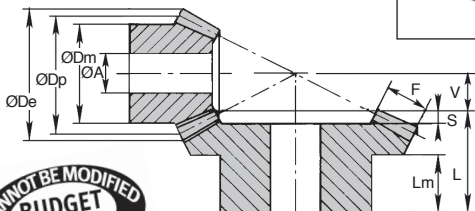


DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Teeth		OD _p	OD _e	F	L	OD _m	Pilot bore not guaranteed				Lm	Price each 1 to 3
	Z	mod						ØA**	V	S	Stock*		
DB1-15/ECO	15	1	15	17,4	5	11,9	13,3	4	10,10	-	6,5	-	-
DB1-30/ECO	30	1	30	30,6	5	15,1	20,3	5	4,90	1,4	9,0	-	-
DB1.5-16/ECO	16	1,5	24	26,68	8	19,5	21	10	16,33	1,5	11,3	✓	18,62 €
DB1.5-32/ECO	32		48	49,34	8	20,0	32	12	7,45	3,0	10,0	✓	29,58 €
DB2-16/ECO	16	2	32	35,57	10	23,0	26	10	22,41	2,0	11,9	✓	23,59 €
DB2-32/ECO	32		64	65,78	10	25,0	40	12	10,21	4,0	10,0	✓	54,29 €
DB2.5-16/ECO	16	2,5	40	44,47	12	27,5	34	12	28,38	2,5	14,4	✓	33,21 €
DB2.5-32/ECO	32		80	82,23	12	25,0	50	15	12,97	5,0	10,0	✓	60,94 €
DB3-16/ECO	16	3	48	53,36	15	28,0	40	15	33,64	3,0	11,6	✓	40,72 €
DB3-32/ECO	32		96	98,68	15	30,0	60	15	15,31	6,0	10,0	✓	76,87 €
DB3.5-16/ECO	16	3,5	56	62,26	18	33,5	48	15	38,83	3,5	14,4	✓	44,66 €
DB3.5-32/ECO	32		112	115,12	18	31,0	70	20	17,77	7,0	10,0	✓	91,01 €
DB4-16/ECO	16	4	64	71,15	20	36,0	50	15	44,81	4,0	13,4	✓	55,72 €
DB4-32/ECO	32		128	131,57	20	32,0	80	20	20,42	8,0	10,0	✓	95,74 €
DB4.5-16/ECO	16	4,5	72	80,05	22	39,5	60	20	51,00	4,5	15,4	-	60,76 €
DB4.5-32/ECO	32		144	148,00	22	36,0	90	20	23,21	9,0	10,0	-	126,10 €
DB5-16/ECO	16	5	80	88,94	25	50,0	60	20	56,06	5,0	21,1	-	66,34 €
DB5-32/ECO	32		160	164,46	25	38,0	100	20	25,52	10,0	10,0	-	151,77 €

*Depending on availability - Dimensions in mm

 Our other products



CAB

Galvanised steel cable, Galvanised steel



SVG

Adjustable latch clamp with strike plate, Stroke from 174mm to 190mm



PSPE22

Conical flexible shaft handlee Ø22, Black PVC



LVT

Miniature motorised actuator 2A, 2 ampers



 
RBGtc

Swivel castor with central hole, Steel - grey rubber - with double b...



GMK17_BR

Clamp for guiding profile, Rounded only - single




B

Steel bevel gear, 1:1



CHMBR

 Reaction arm, CHM and CHMR gear reducers reaction arm



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane



RAGFLOW

Floway2® roller track, Roller track



BPM

Slotted spring plunger with ball tip, Stainless steel 303



MEFC

Flanged sintered ferrous bush, Self-lubricating FP20 ferrous alloy M...

Complementary products



DB

Steel bevel gear, 2:1