

Ratio 2:1


Steel C43

- Module 1.5 to 5
- Teeth conform to DIN 3967 except for Module 1 models which are Gleason
- Pressure angle: 20°
- Material: steel C43
- A pair requires 2 gears



Info.

- **Pilot bore dimensions given as a guide only and are subject to change.

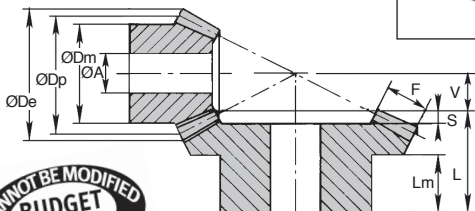

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Teeth		OD _p	OD _e	F	L	OD _m	Pilot bore not guaranteed			Lm	Price each 1 to 3	
	Z	mod						ØA**	V	S			
DB1-15/ECO	15		15	17,4	5	11,9	13,3	4	10,10	-	6,5	-	-
DB1-30/ECO	30		30	30,6	5	15,1	20,3	5	4,90	1,4	9,0	-	-
DB1.5-16/ECO	16	1,5	24	26,68	8	19,5	21	10	16,33	1,5	11,3	✓	18,62 €
DB1.5-32/ECO	32		48	49,34	8	20,0	32	12	7,45	3,0	10,0	✓	29,58 €
DB2-16/ECO	16	2	32	35,57	10	23,0	26	10	22,41	2,0	11,9	✓	23,59 €
DB2-32/ECO	32		64	65,78	10	25,0	40	12	10,21	4,0	10,0	✓	54,29 €
DB2.5-16/ECO	16	2,5	40	44,47	12	27,5	34	12	28,38	2,5	14,4	✓	33,21 €
DB2.5-32/ECO	32		80	82,23	12	25,0	50	15	12,97	5,0	10,0	✓	60,94 €
DB3-16/ECO	16	3	48	53,36	15	28,0	40	15	33,64	3,0	11,6	✓	40,72 €
DB3-32/ECO	32		96	98,68	15	30,0	60	15	15,31	6,0	10,0	✓	76,87 €
DB3.5-16/ECO	16	3,5	56	62,26	18	33,5	48	15	38,83	3,5	14,4	✓	44,66 €
DB3.5-32/ECO	32		112	115,12	18	31,0	70	20	17,77	7,0	10,0	✓	91,01 €
DB4-16/ECO	16	4	64	71,15	20	36,0	50	15	44,81	4,0	13,4	✓	55,72 €
DB4-32/ECO	32		128	131,57	20	32,0	80	20	20,42	8,0	10,0	✓	95,74 €
DB4.5-16/ECO	16	4,5	72	80,05	22	39,5	60	20	51,00	4,5	15,4	-	60,76 €
DB4.5-32/ECO	32		144	148,00	22	36,0	90	20	23,21	9,0	10,0	-	126,10 €
DB5-16/ECO	16	5	80	88,94	25	50,0	60	20	56,06	5,0	21,1	-	66,34 €
DB5-32/ECO	32		160	164,46	25	38,0	100	20	25,52	10,0	10,0	-	151,77 €

*Depending on availability - Dimensions in mm

Our other products



VRC1

Retaining clamp,
single sided, Single
sided



 
CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm



PLC_PLT

Magnetic stud with
threaded hole, With
threaded hole



PO

Pull handle - Multi-
sector, Smooth hole



PR40

Articulated foot Ø40,
Ø 40



BOX-TOR-G

Box set of Nitrile O-
rings in nitrile, 3.00 x
1.50mm to 30.20 x
3.00



 
LVT

Miniature motorised
actuator 2A, 2 ampers



CLQ

12.7mm wide steel
feeler strip on rolls,
Feeler strip on rolls



PRZ

Wear strip for slat top
chain, Z profile to be
clipped




J66

Spur gear coaxial
gearbox, from 0.90 to
2.80 Nm - Inline



PM2

 Worm and wheel set,
Machined plastic
(delrin)



LSM

Stainless steel 316L
leadscrew, Stainless
steel - 1 thread

Complementary products



DB

Steel bevel gear, 2:1