

Idler for plate chain



DBL805

For chain range 805


- For use with CAP805/SS plate chains

- Materials:

Low friction acetal

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

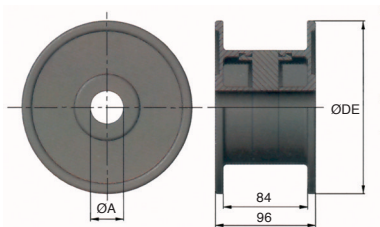

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

Our other products



SLBW
Indexing plunger, weldable, Weldable - Steel



MAC
Carabiner DIN5299 steel, Steel



PTGR
Tensioner pulley, For round belts



PO
Pull handle - Multi-sector, Tapped recessed insert



YG2
HEAVY DUTY spur gear, Steel 35NCD6



CHAR
Spring hinge, screwed



GLB
Small 6 lobe female handle, Technopolymer - Stainless steel



DOMI80
Accessories, Clamping lever



VQT
Quarter-turn clamp lock, Plastic or stainless steel button



ATZY
Diabolo shaped elasto mount, Steel



CHMR90
Worm and wheel gear reducer, up to 540 Nm



RT25
Self-centering flanged locking assembly, Medium/high torque

Complementary products



CAP805
Slat top chain stainless steel, Large range 805



PR821
Idler sprocket for slat top chain, Ranges 821 and 805