


# Idler for plate chain



## DBL805

## For chain range 805

- For use with CAP805/SS plate chains
- Materials:
  - Low friction acetal
- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)
- For dimensions and bore tolerances,  
please refer to technical pages

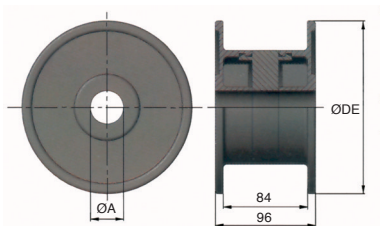

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

## Our other products



CABPVC

PVC covered galvanised steel cable, Galvanised steel with



BCM\_T

Driving collar, Driving collar



PRF\_VTM

Hammerhead screw, Hammerhead screw



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm



MDB\_MTB

Moulded plastic bevel gear (nylon), 3:1



KB\_WW

Closed linear precision bearing, Economy range



MFB\_MHB

Moulded plastic bevel gear (nylon), 4:1



FF30

Offset spur gear reducer, from 21.50 to 83 Nm



VTLB

Three-lobed knob, Thermoplastic / Brass or stainless steel insert



ACL

Joints for aluminium profile, Variable angle hinge



CHB

Double output shaft, For CHB gearbox



PSG05HC

Skive hobbled spur gears - precision range, Case hardened steel 20NCD2

## Complementary products



CAP805

Slat top chain stainless steel, Large range 805



PR821

Idler sprocket for slat top chain, Ranges 821 and 805