


Idler for plate chain



DBL805

For chain range 805

- For use with CAP805/SS plate chains
- Materials:
 - Low friction acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)
- For dimensions and bore tolerances,
please refer to technical pages

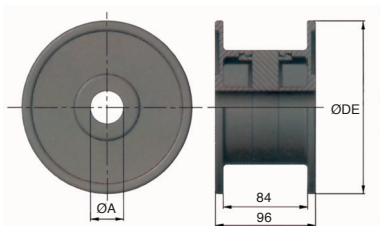

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

Our other products



 
Articulated foot with sheet metal base Ø80, Articulated foot



Automatic chain tensioner, With wide guide



Sealed flange bearing unit for Food Industry, cover




Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



Stainless steel/Polymer flanged bearing, Polymer and stainless steel



Hexagonal nut DIN934, Steel (Class 6|8)

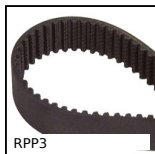

RPP heavy duty timing belt, RPP3



Strike for toggle latch, 15mm



 
Fixed anti-vibration foot mount, Vibration-dampening



Right angled gearbox, double output shafts, up to 1.77 Nm



Articulated levelling foot, pressed base Ø50, 4000N



Aluminium shaft for linear guide, Aluminium

Complementary products



Slat top chain stainless steel, Large range 805



Idler sprocket for slat top chain, Ranges 821 and 805