


Idler for plate chain



DBL805

For chain range 805

- For use with CAP805/SS plate chains
- Materials:
 - Low friction acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)
- For dimensions and bore tolerances,
please refer to technical pages

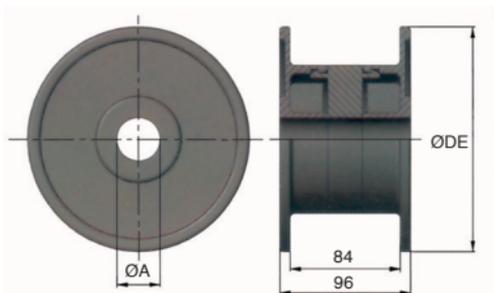

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty. | 1+ | 5+ | 10+ |
| Disc. | List | -5% | On request |

| Part number | ØDE | Bore ØA | Weight (kg) | Price each 1 to 4 |
|--------------|-----|------------|----------------|----------------------|
| DBL805-19-25 | 117 | 25 | 0,3 | 15,69 € |
| DBL805-19-30 | 117 | 30 | 0,3 | 15,69 € |
| DBL805-19-35 | 117 | 35 | 0,3 | 15,69 € |
| DBL805-19-40 | 117 | 40 | 0,3 | 15,69 € |
| DBL805-21-25 | 129 | 25 | 0,3 | 16,14 € |
| DBL805-21-30 | 129 | 30 | 0,3 | 16,14 € |
| DBL805-21-35 | 129 | 35 | 0,3 | 16,14 € |
| DBL805-21-40 | 129 | 40 | 0,3 | 16,14 € |
| DBL805-23-25 | 141 | 25 | 0,3 | 17,36 € |
| DBL805-23-30 | 141 | 30 | 0,3 | 17,36 € |
| DBL805-23-35 | 141 | 35 | 0,3 | 17,36 € |
| DBL805-23-40 | 141 | 40 | 0,3 | 17,36 € |
| DBL805-25-25 | 153 | 25 | 0,4 | 18,07 € |
| DBL805-25-30 | 153 | 30 | 0,4 | 18,07 € |
| DBL805-25-35 | 153 | 35 | 0,4 | 18,07 € |
| DBL805-25-40 | 153 | 40 | 0,4 | 18,07 € |

Dimensions in mm

Our other products



DIA

Ring operated locking bolt, with ring



RDCtss

Rigging screw with 2 jaws stainless steel, Stainless steel



PSG2

Spur gear - precision range, Case hardened steel 20NCD2



PSG3S

Spur gear - precision range, Stainless steel 303



PRF4545_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm




RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



SBF

Sealed flange bearing unit for Food Industry, cover

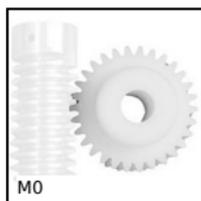

M0

Worm and wheel set, Machined plastic (delrin)



RLXAC8

Free roller, Steel



PTA80

Articulated levelling foot, pressed base Ø80, 10000N



VRC1

Retaining clamp, single sided, Single sided



QNUP

Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...

Complementary products



CAP805

Slat top chain stainless steel, Large range 805



PR821

Idle sprocket for slat top chain, Ranges 821 and 805