

Idler for plate chain



DBL805

For chain range 805


- For use with CAP805/SS plate chains

- Materials:

Low friction acetal

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

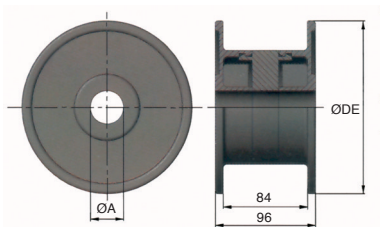

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

Our other products



CHTRP

Single and dual output gearboxes, Up to 87,3Nm




CHAE4060PA

Decorative asymmetric screwed hinge, Polyamide




PF30

 Worm and wheel gear reducer, up to 8.80 Nm



BMF

 Knurled knob - female, Knurled - through threaded



CRM

Moulded nylon rack, Nylon




BLHB50

Right angled gearbox, bored shafts, up to 30 Nm



PGT

 Sliding profile, Sliding panel support



CYS

Internal circlip DIN472, internal DIN 472



VTH

Hexagonal headed bolts, Steel class 8.8



SSDB

Stainless steel bevel gear, 2:1



SVT15

Screwjack with travelling screw, with



PGMT

Pull handle, Stainless steel

Complementary products



CAP805

Slat top chain stainless steel, Large range 805



PR821

Idler sprocket for slat top chain, Ranges 821 and 805